



TRANSFER PLUG , PASSIV

UFL 40-pole

Ribbon cable connector
40-pole
Spring clamp terminals
Via the combined fixing mechanism, connectors with or without strain relief can be connected.
for plugs with or without strain relief (DIN 41651); for plugs with strain relief, it may be necessary to remove the bottom hook

제품 링크

일러스트

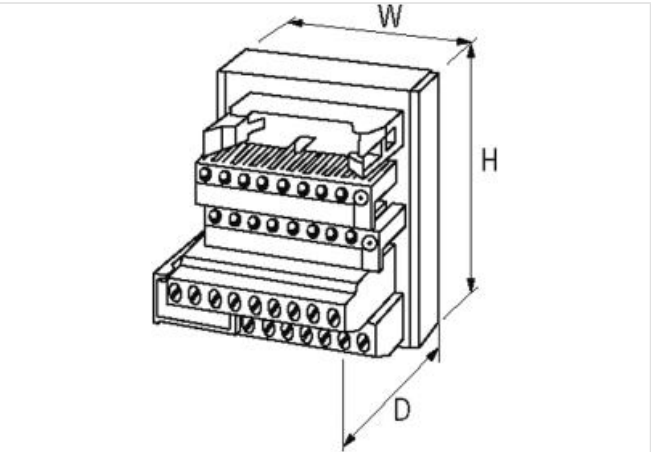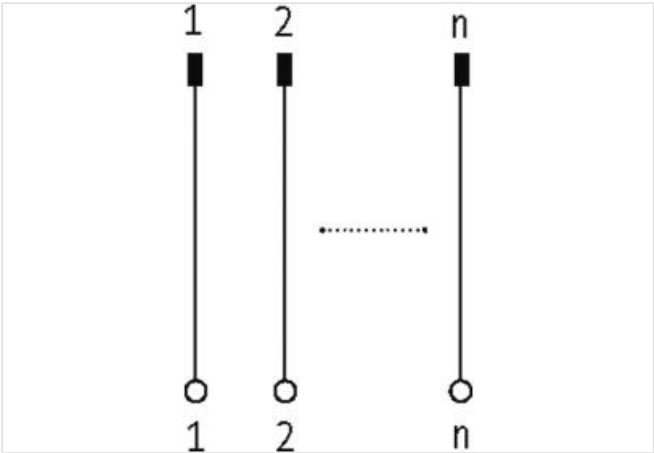

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27260710
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283

GTIN	4048879023887
세번부호	85366990
포장단위	10
Electrical data Supply	
Operating voltage DC	24 V
Operating current max.	1 A
Installation Connection	
Connection	Spring clamp terminals FK
Device protection Electrical	
Pollution Degree	2
Overvoltage category (EN 60664-1)	III
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	70 mm
Depth	70 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C