

EUROCARD HOLDER



SKP 96/IC (ST)

Screw terminals
96-pole C (EN 60603)
Row a, b, c

With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.
The D2 size is for a card without a front plate.
To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

제품 링크

일러스트

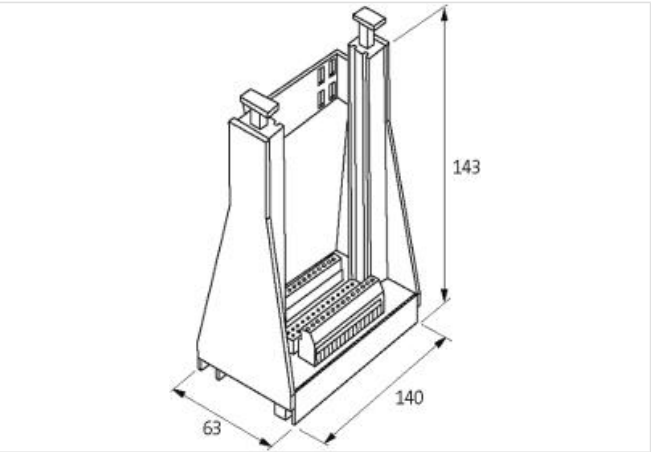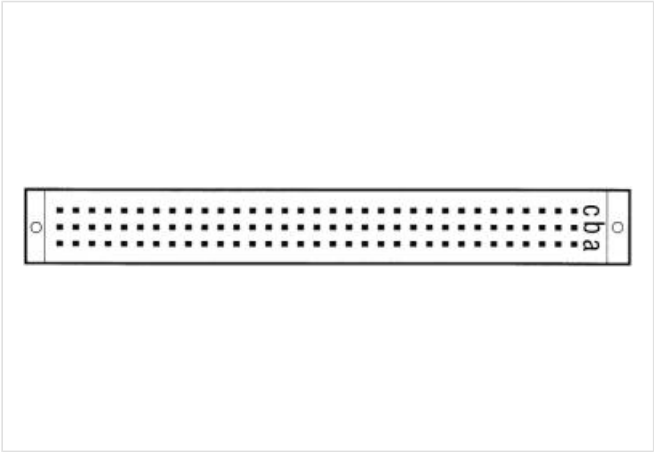

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27260710
ECLASS-6.1	27260704
ECLASS-7.0	27440402
ECLASS-8.0	27440402
ECLASS-9.0	27440402
ECLASS-10.1	27440402
ECLASS-11.1	27460201
ECLASS-12.0	27460201

ETIM-5.0	EC002780
GTIN	4048879039956
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	125 V
Operating current max.	1 A
Installation	
Connection cross-section solid max.	4 mm²
Installation Pin assignment	
No. of poles	96
Device protection Electrical	
Overvoltage category (EN 60664-1)	I
Device protection Media	
Flame resistance	flame retardant
Mechanical data	
Type of socket connector	C (EN 60603)
Mechanical data Material data	
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	140 mm
Width	62 mm
Depth	1770 mm