


MSVD POWER SOCKET NEMA WITH LED

Mounting rail

USA (NEMA 5-15)
Screw terminals
LED (yellow)

제품 링크

일러스트

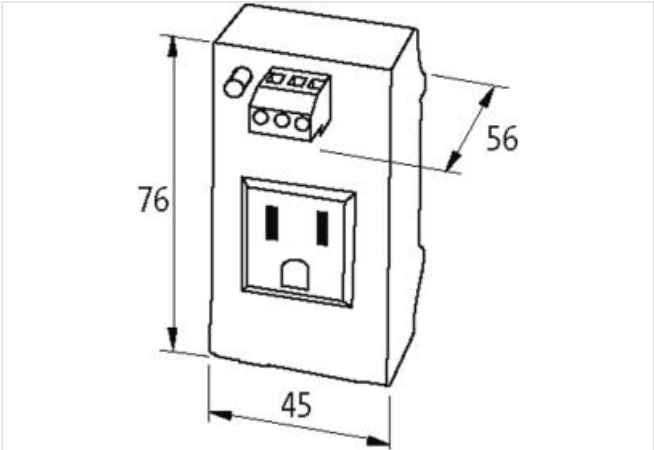

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
GTIN	4048879039642
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	127 V
Operating current	15 A
Installation	
Connection cross section max.	2,5 mm²
AWG number	14
Installation Connection	
Connection	Screw terminals SK
Mechanical data Mounting data	

이 데이터 시트에 포함된 정보는 최대한의 주의로 작성되었습니다.
2024-05-21

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	45 mm
Depth	56 mm