



MET SINGLE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:250VA IN:220...530VAC±20VAC OUT:230VAC

Single-phase safety transformer
250 VA
Isolation class T 40/B
Other voltages on request.

제품 링크

일러스트

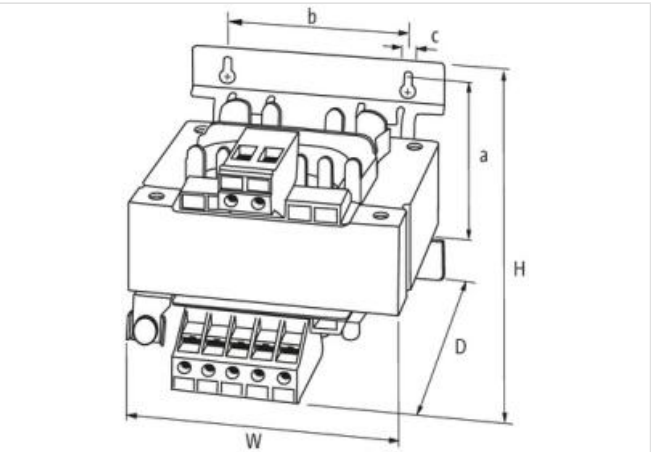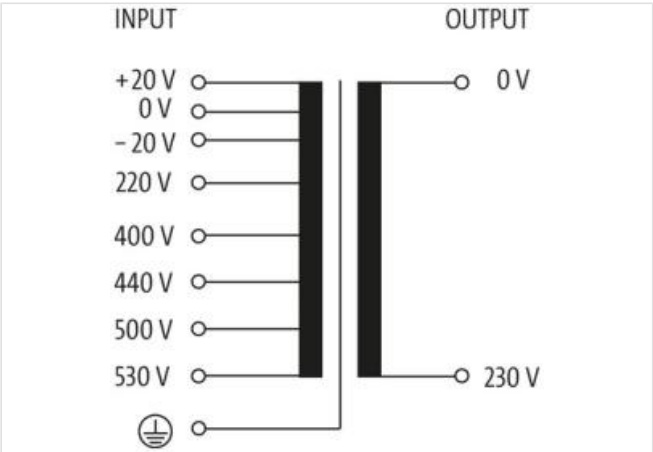

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27031202
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002485
GTIN	4048879073943
세번부호	85043180
포장단위	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage 1 AC	220 V
Input voltage 2 AC	530 V
Input voltage AC	220, 400, 440, 500, 530
Input voltage AC	220 V
Input current at input voltage 1 AC	1,28 A
Input current at input voltage 2 AC	0,53 A
Max. inrush current	18 A
Short-circuit current	21 A
Electrical data Output	
Output voltage AC	230 V
Output voltage adjustable	no
Power rating AC max.	250 VA
Device protection Electrical	
Insulation test voltage input - output	6,2 kV
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochaufhängung
Mounting dimension a	74,4 mm
Mounting dimension b	90 mm
Mounting dimension c	5,8 mm
Height	92,4 mm
Width	120 mm
Depth	122 mm
Diameter bore	5,8 mm
Length bore	12 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-20 °C
Storage temperature max.	80 °C
Conformity	
Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0