


MET SINGLE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:1000VA IN:200/440VAC OUT:110/230VAC

Single-phase - Control and Isolation Transformers
1000 VA
Isolation class T 60/B
Condensation not permitted

제품 링크

일러스트

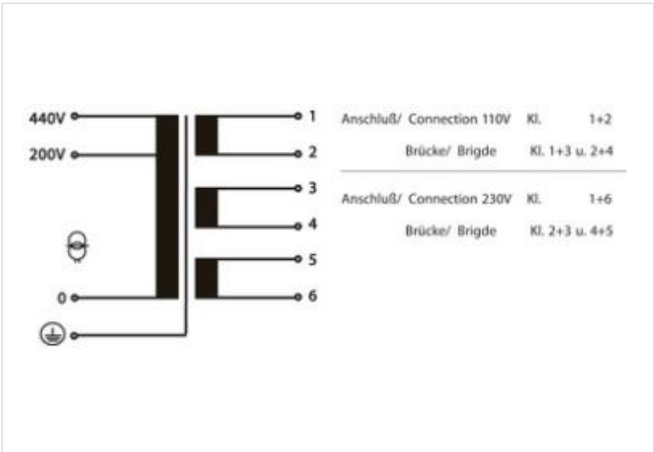

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27031202
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302

ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002485
GTIN	4048879073929
세번부호	85043180
포장단위	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage 1 AC	200 V
Input voltage 2 AC	440 V
Input current at input voltage 1 AC	5,6 A
Input current at input voltage 2 AC	2,55 A
Inrush current at input voltage 1	124 A
Inrush current at input voltage 2	54 A
Short-circuit current at input voltage 1	158 A
Short-circuit current at input voltage 2	63 A
Electrical data Output	
Output voltage AC 1	110 V
Output voltage AC 2	230 V
Output voltage adjustable	yes
Power rating AC max.	1000 VA
Device protection Electrical	
Insulation test voltage input - output	4 kV
Mechanical data Mounting data	
Suitable for mounting type	Schlüssellochaufhängung
Mounting dimension a	112 mm
Mounting dimension b	135 mm
Mounting dimension c	7 mm
Height	138 mm
Width	174 mm
Depth	160 mm
Diameter bore	7 mm
Length bore	15 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Conformity	
Product standard	EN 61558-1, EN 61558-2-4, EN 62041 category 0