


MDST THREE-PHASE AUTOTRANSFORMER

P:5200VA IN:3x400/440VAC OUT:3x230VAC

Autotransformer
5 200 VA
Isolation class T 40/B
Other voltages on request.

제품 링크

일러스트

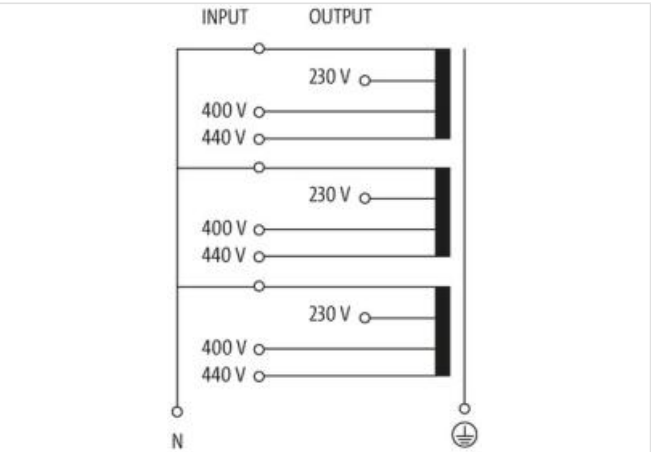

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27031301
ECLASS-7.0	27031301
ECLASS-8.0	27031301
ECLASS-9.0	27031301
ETIM-5.0	EC002485
GTIN	4048879073806
세번부호	85043200
포장단위	1

Electrical data | Supply

Power frequency50 ... 60 Hz

Electrical data | Input

Input voltage 1 AC	400 V
Input voltage 2 AC	440 V
Input voltage AC	400 V
Input current at input voltage 1 AC	7,7 A
Input current at input voltage 2 AC	7 A
Max. inrush current	52 A
Short-circuit current	657 A

Electrical data | Output

Output voltage	3 × 230 V AC
Output voltage AC	230 V
Output voltage adjustable	no
Power rating AC max.	5200 VA

Device protection | Electrical

Insulation test voltage input - PE 3 kV

Mechanical data | Mounting data

Suitable for mounting type	Schlüssellochauhängung
Mounting dimension a	125 mm
Mounting dimension b	190 mm
Mounting dimension c	10 mm
Height	206 mm
Width	240 mm
Depth	152 mm
Diameter bore	10 mm
Length bore	18 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-2-6, EN 62041 category 0
------------------	-----------------------------------