


MST SINGLE-PHASE CONTROL AND ISOLATION TRANSFORMER

P:2500VA IN:690VAC OUT:230VAC

Single-phase - Control and Isolation Transformers  
2500 VA  
Isolation class T 40/B  
Other voltages on request.

제품 링크

일러스트

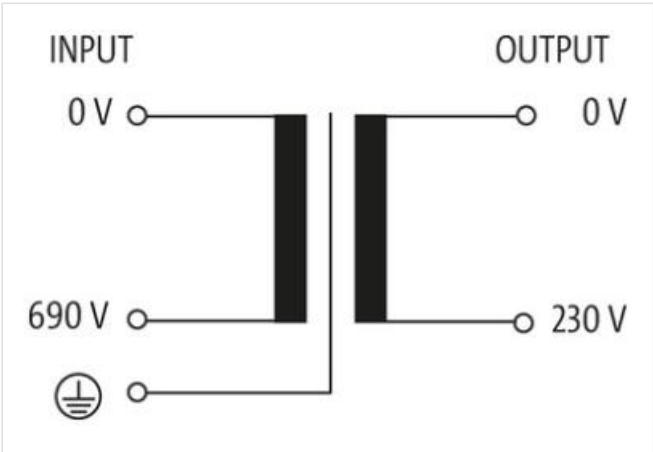

실제 제품은 이미지와 다를 수 있습니다.

| 제품자료       |               |
|------------|---------------|
| ECLASS-6.0 | 27031202      |
| ECLASS-7.0 | 27031202      |
| ECLASS-8.0 | 27031202      |
| ECLASS-9.0 | 27031202      |
| ETIM-5.0   | EC002485      |
| GTIN       | 4048879283229 |
| 세번부호       | 85043200      |
| 포장단위       | 1             |

| Electrical data   Supply |              |
|--------------------------|--------------|
| Power frequency          | 50 ... 60 Hz |

| Electrical data   Input                  |                                               |
|------------------------------------------|-----------------------------------------------|
| Input voltage 1 AC                       | 690 V                                         |
| Input voltage AC                         | 690 V                                         |
| Current input AC                         | 3,9 A                                         |
| Max. inrush current                      | 64 A                                          |
| Short-circuit current                    | 127 A                                         |
| Electrical data   Output                 |                                               |
| Output voltage AC                        | 230 V                                         |
| Output voltage adjustable                | no                                            |
| Power rating AC max.                     | 2500 VA                                       |
| Device protection   Electrical           |                                               |
| Insulation test voltage input - output   | 6,5 kV                                        |
| Mechanical data   Mounting data          |                                               |
| Suitable for mounting type               | Long-hole mounting                            |
| Mounting dimension a                     | 130 mm                                        |
| Mounting dimension b                     | 150 mm                                        |
| Mounting dimension c                     | 10 mm                                         |
| Height                                   | 250 mm                                        |
| Width                                    | 197 mm                                        |
| Depth                                    | 174 mm                                        |
| Diameter bore                            | 10 mm                                         |
| Length bore                              | 18 mm                                         |
| Environmental characteristics   Climatic |                                               |
| Operating temperature min.               | -20 °C                                        |
| Operating temperature max.               | 40 °C                                         |
| Storage temperature min.                 | -40 °C                                        |
| Storage temperature max.                 | 80 °C                                         |
| Conformity                               |                                               |
| Product standard                         | EN 61558-1, EN 61558-2-4, EN 62041 category 0 |
| Connection type 3                        |                                               |
| Connection type 1                        | Input                                         |
| Connection type 2                        | Output                                        |
| Connection                               | Screw terminals SK                            |
| Family construction form                 | terminal                                      |
| Gender                                   | female                                        |
| No. of poles                             | 2                                             |
| PIN 2                                    | 690 V                                         |
| Connection                               | Screw terminals SK                            |
| Family construction form                 | terminal                                      |
| Gender                                   | female                                        |
| No. of poles                             | 2                                             |
| PIN 2                                    | 230 V                                         |
| Connection                               | Screw terminals SK                            |
| Family construction form                 | terminal                                      |
| Gender                                   | female                                        |
| Color contact carrier                    | metallic                                      |
| No. of poles                             | 1                                             |
| PIN 1                                    | PE                                            |