

VALVE PLUG SUPPRESSOR FORM A - 18MM

RC and LED, 230VAC/DC/10VA/W



230 V AC/DC

RC + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

제품 링크

일러스트

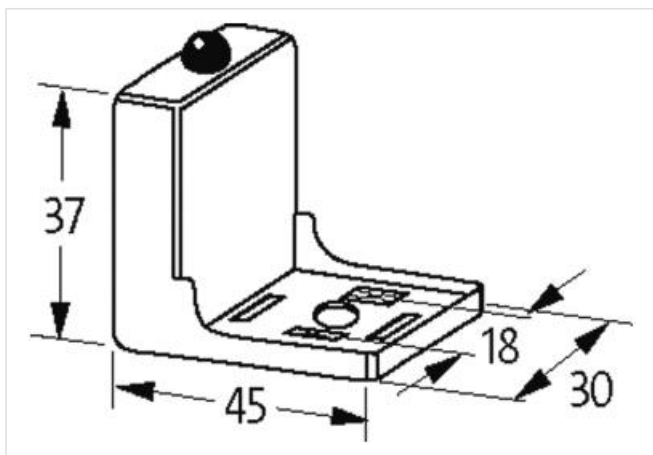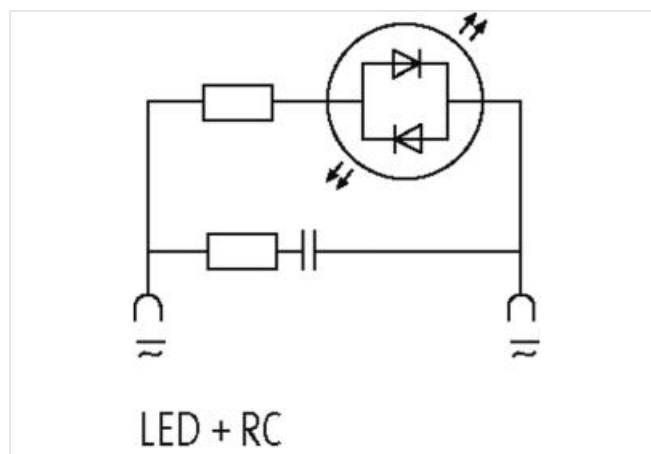

실제 제품은 이미지와 다를 수 있습니다.



제품자료

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879012188
세번부호	85363010
포장단위	1
Electrical data	
Capacity CX	20 ms
Holding power max.	10 W
Electrical data Supply	
Cut-off peak voltage max.	300 V
Electrical data Input	
Input voltage AC min.	110 V
Input voltage AC max.	250 V
Input voltage DC min.	110 V
Input voltage DC max.	250 V
Diagnostics	
Status indication LED	yellow
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Coating contact	silver-plated
Color housing	black
Material housing	PA
Material contact	Bronze
Mechanical data Mounting data	
Height	37 mm
Width	45 mm
Depth	30 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C