



VALVE PLUG SUPPRESSOR FORM B - 10MM

Zener diode and LED, 24VDC/100VA/W

24 V AC/DC  
Z-Diode + LED  
with suppression  
Remove plug gasket when fitting adapter. Other LED colors on request.  
suitable for 0 and 180° installation

제품 링크

일러스트

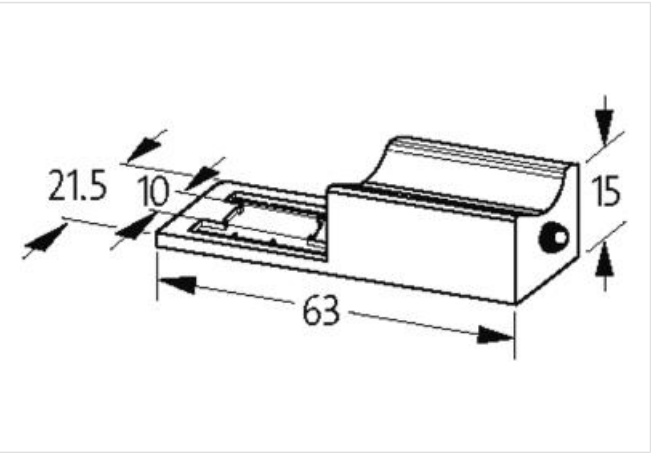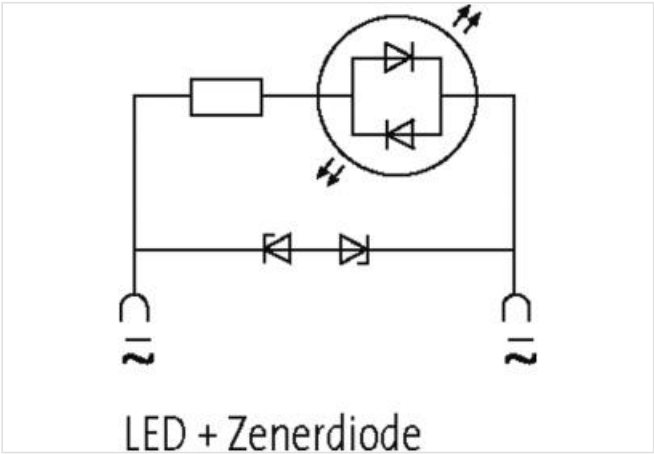

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료       |          |
|------------|----------|
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-9.0 | 27371013 |

|                                          |                 |
|------------------------------------------|-----------------|
| ECLASS-10.1                              | 27371013        |
| ECLASS-11.1                              | 27371013        |
| ECLASS-12.0                              | 27371013        |
| ETIM-5.0                                 | EC000197        |
| GTIN                                     | 4048879011495   |
| 세번부호                                     | 85363010        |
| 포장단위                                     | 1               |
| Electrical data                          |                 |
| Capacity CX                              | 20 ms           |
| Holding power max.                       | 100 W           |
| Electrical data   Supply                 |                 |
| Cut-off peak voltage max.                | 55 V            |
| Electrical data   Input                  |                 |
| Input voltage AC min.                    | 18 V            |
| Input voltage AC max.                    | 30 V            |
| Input voltage DC min.                    | 18 V            |
| Input voltage DC max.                    | 30 V            |
| Diagnostics                              |                 |
| Status indication LED                    | yellow          |
| Device protection   Media                |                 |
| Flame resistance                         | flame retardant |
| Mechanical data   Material data          |                 |
| Coating contact                          | silver-plated   |
| Color housing                            | black           |
| Material housing                         | PA              |
| Material contact                         | Bronze          |
| Mechanical data   Mounting data          |                 |
| Height                                   | 15 mm           |
| Width                                    | 63 mm           |
| Depth                                    | 21,5 mm         |
| Environmental characteristics   Climatic |                 |
| Operating temperature min.               | -20 °C          |
| Operating temperature max.               | 60 °C           |
| Housing temperature max. (EN 61347-2-13) | 130 °C          |