

CAP BIG WITH PLUG.SPRING-TERM 21-POLE

For use with 4-,6-,8-way d-box M12 5--pole

Cap for 4-, 6-, and 8-way distribution box, 5-pole



Spring clamp plug-in terminals

Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

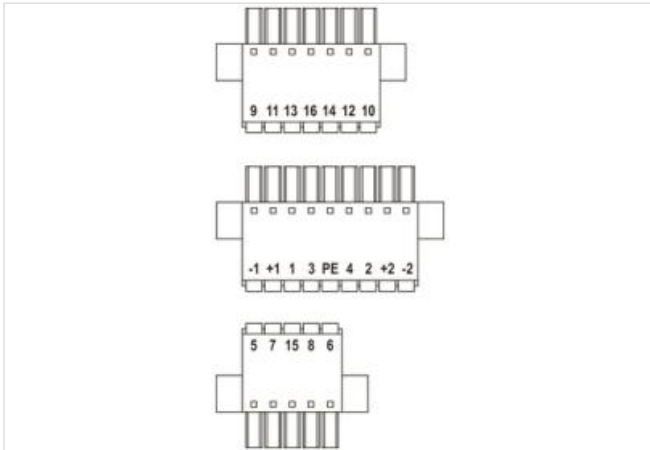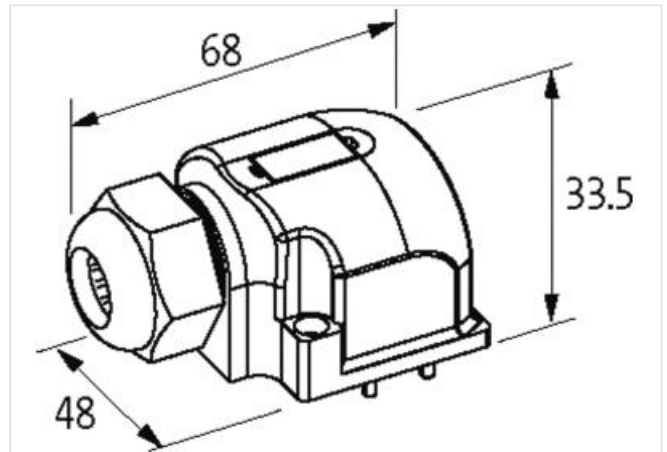

실제 제품은 이미지와 다를 수 있습니다.

제품자료

ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
GTIN	4048879058018
세번부호	85369010

포장단위	1
Electrical data Supply	
Total current max.	8 A
Installation	
Connection cross section max.	1,5 mm²
AWG number max.	16
Installation Connection	
Connection	Spring clamp terminals FK
Mechanical data Mounting data	
Height	33,5 mm
Width	48 mm
Depth	68 mm
Connection type 1	
Family construction form	Cap
No. of poles	21