



MIRO 6.2 115V-1U OUTPUT RELAY WITH LEAKAGE

CURRENT SUPPRESSION

1 NO/NC contact
6 A
115 V AC/DC
Spring clamp terminals
This module includes a leakage current suppression (LCS) in order to ensure safe shutdown of the module when activated with semiconductors (e.g. Triacs).

제품 링크

일러스트

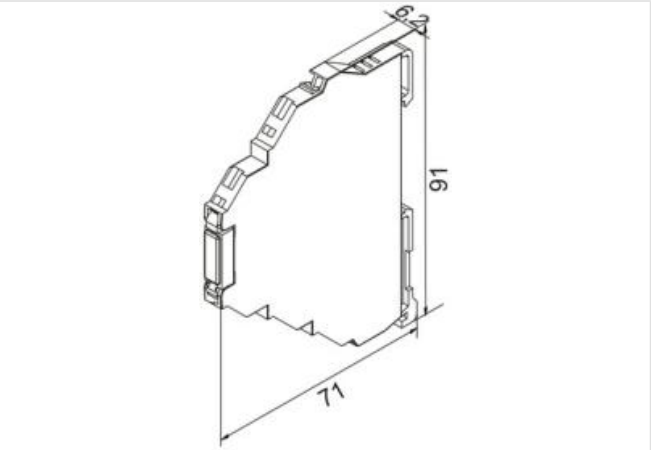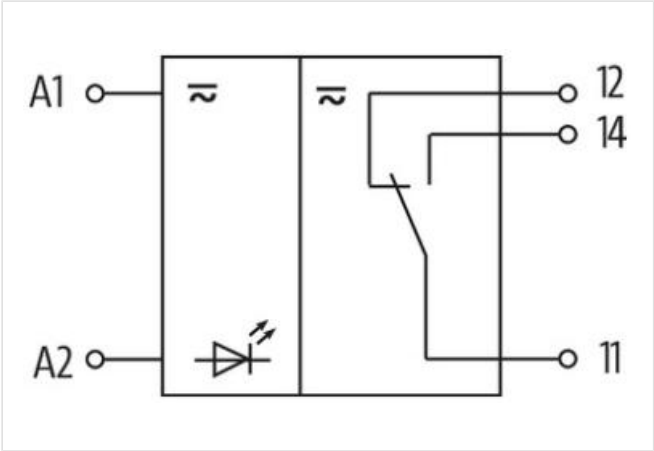

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371601
ECLASS-6.1	27371601
ECLASS-7.0	27371601
ECLASS-8.0	27371601

ECLASS-9.0	27371601
ECLASS-10.1	27371601
ECLASS-11.1	27371601
ECLASS-12.0	27371601
ETIM-5.0	EC001437
GTIN	4048879879781
세번부호	85364900
포장단위	1
Electrical data Input	
Input voltage AC	115 V
Input voltage AC min.	92 V
Input voltage AC max.	132 V
Input voltage DC	115 V
Input voltage DC min.	92 V
Input voltage DC max.	132 V
Input current	8 mA
Electrical data Output	
Utilization category AC-12 (EN IEC 60947-5-1)	6 A @ 24, 6 A @ 110 V, 6 A @ 230 V
Utilization category AC-15 (EN IEC 60947-5-1)	3 A @ 24 V, 3 A @ 110 V, 3 A @ 230 V
Utilization category DC-13 (EN IEC 60947-5-1)	1 A @ 24 V, 0,2 A @ 110 V, 0,1 A @ 230 V
Power rating AC max.	1500 VA
Power rating DC max.	120 W
Switching voltage AC max.	250 V
Switching voltage DC max.	250 V
Switching current DC	100 mA
Switching current max.	6 A
Diagnostics	
Status indication LED	green
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Electrical lifetime	60000 Cycles
Device protection Mechanical	
Mechanical endurance	10000000 Cycles
Mechanical data	
Drop-out time max.	5 ms
Response time max.	12 ms
Bounce time max.	3 ms
Mechanical data Material data	
Material contact	Ag Sn O2
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	91 mm
Width	6,2 mm
Depth	71 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	60 °C
Connection type 5	
Connection	Spring clamp terminals FK

Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	12
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	11
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	14
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	A 1
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	A 2