


MET 1-PHASE CONTROL AND ISOLATION TRANSFORMER

P: 800VA IN: 230VAC+/- 5% OUT: 230VAC

Single-phase - Control and Isolation Transformers
800 VA
Spring clamp terminals
Isolation class T 60/B

제품 링크

일러스트

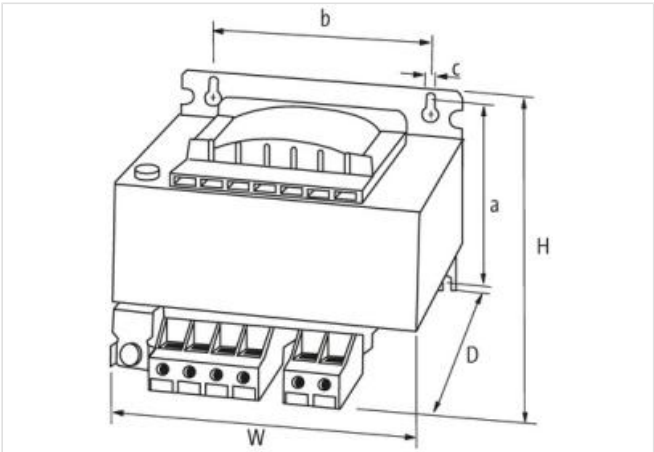

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27031302
ECLASS-6.1	27031302
ECLASS-7.0	27031302
ECLASS-8.0	27031302
ECLASS-9.0	27031302
ECLASS-10.1	27031302
ECLASS-11.1	27031302
ECLASS-12.0	27031302
ETIM-5.0	EC002486
GTIN	4048879066440
세번부호	85043180
포장단위	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	230 V
Input voltage AC min.	218,5 V
Input voltage AC max.	241,5 V
Current input AC	3,75 A
Max. inrush current	51,78 A

이 데이터 시트에 포함된 정보는 최대한의 주의로 작성되었습니다.
2024-05-28

Short-circuit current143,2 A

Electrical data | Output

Output voltage AC230 V
Output voltage adjustableno
Power rating AC max.800 VA

Device protection | Electrical

Insulation test voltage input - output4 kV

Mechanical data | Mounting data

Suitable for mounting typeSchlüssellochaufhängung
Mounting dimension a92 mm
Mounting dimension b135 mm
Mounting dimension c7 mm
Height118 mm
Width175 mm
Depth160 mm
Diameter bore7 mm
Length bore11 mm

Environmental characteristics | Climatic

Operating temperature min.-20 °C
Operating temperature max.60 °C
Storage temperature min.-40 °C
Storage temperature max.80 °C

Conformity

Product standardEN 61558-1, EN 61558-2-4, EN 62041 category 0