

SIEMENS CONTACTOR SUPPRESSOR

RC, 230VAC/DC



230 V AC/DC

RC

For other configurations and voltages, please inquire.

제품 링크

일러스트

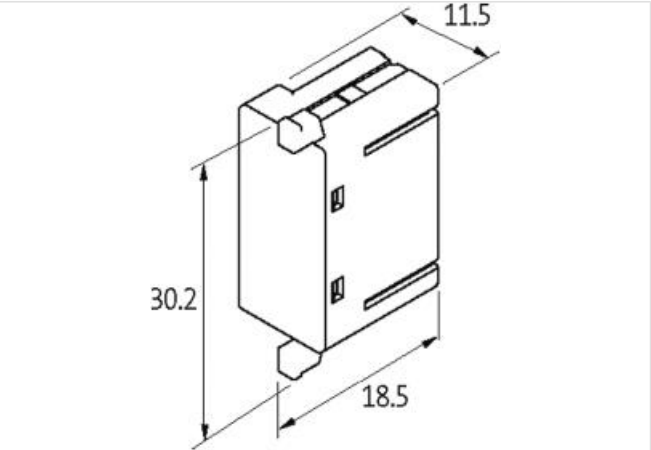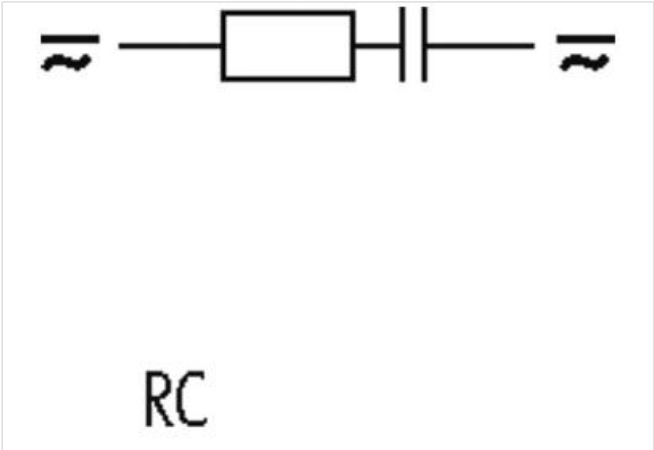

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |          |
|-------------|----------|
| ECLASS-6.0  | 27371013 |
| ECLASS-6.1  | 27371013 |
| ECLASS-7.0  | 27371013 |
| ECLASS-8.0  | 27371013 |
| ECLASS-9.0  | 27371013 |
| ECLASS-10.1 | 27371013 |

|                                          |                     |
|------------------------------------------|---------------------|
| ECLASS-11.1                              | 27371013            |
| ECLASS-12.0                              | 27371013            |
| ETIM-5.0                                 | EC002498            |
| GTIN                                     | 4048879010887       |
| 세번부호                                     | 85363010            |
| 포장단위                                     | 1                   |
| Compatibility   Compatible with          |                     |
| Appropriate contactors                   | 3 RT 20.25/26/27/28 |
| Electrical data                          |                     |
| Damping factor                           | 1.5× UN             |
| Electrical data   Input                  |                     |
| Input voltage AC min.                    | 127 V               |
| Input voltage AC max.                    | 250 V               |
| Input voltage DC min.                    | 127 V               |
| Input voltage DC max.                    | 250 V               |
| Installation   Connection                |                     |
| Connection information                   | Plug contact        |
| Device protection   Media                |                     |
| Flame resistance                         | flame retardant     |
| Mechanical data   Material data          |                     |
| Combustibility class housing (UL94)      | V-0                 |
| Material housing                         | Plastic             |
| Mechanical data   Mounting data          |                     |
| Height                                   | 18,5 mm             |
| Width                                    | 30,2 mm             |
| Depth                                    | 11,5 mm             |
| Environmental characteristics   Climatic |                     |
| Operating temperature min.               | -20 °C              |
| Operating temperature max.               | 70 °C               |