


MIRO 6.2 pluggable Plug-in module Optocoupler

IN: 24 VDC - OUT: 24 VDC / 6 A


Transistor 6 A  
24 V DC

제품 링크

일러스트

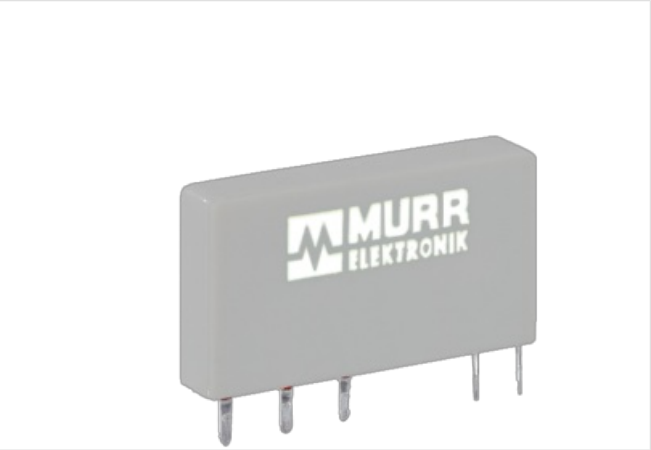

실제 제품은 이미지와 다를 수 있습니다.

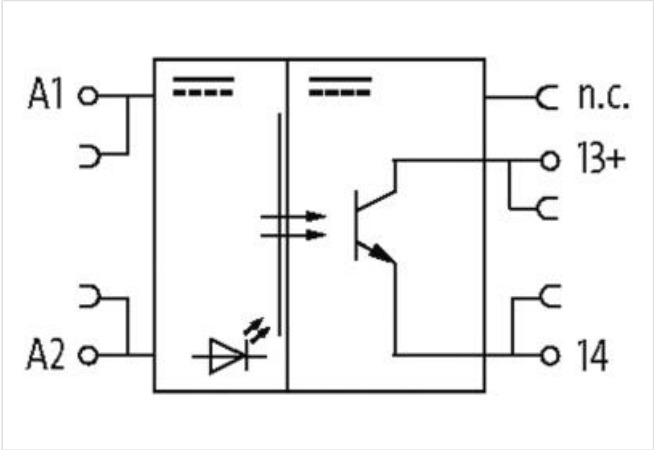

제품자료

|             |               |
|-------------|---------------|
| ECLASS-6.0  | 27371604      |
| ECLASS-6.1  | 27371604      |
| ECLASS-7.0  | 27371604      |
| ECLASS-8.0  | 27371604      |
| ECLASS-9.0  | 27371604      |
| ECLASS-10.1 | 27371604      |
| ECLASS-11.1 | 27371604      |
| ECLASS-12.0 | 27371604      |
| ETIM-5.0    | EC001504      |
| GTIN        | 4048879535175 |
| 세번부호        | 85414900      |
| 포장단위        | 1             |

Electrical data | Input

|                       |      |
|-----------------------|------|
| Input voltage DC      | 24 V |
| Input voltage DC min. | 18 V |
| Input voltage DC max. | 30 V |
| Input current         | 9 mA |

Electrical data | Output

|                                    |        |
|------------------------------------|--------|
| Switch off delay max.              | 31 µs  |
| Forward voltage max.               | 240 mV |
| Switching frequency inductive max. | 50 Hz  |
| Switching frequency ohmic max.     | 500 Hz |

이 데이터 시트에 포함된 정보는 최대한의 주의로 작성되었습니다.  
2024-04-24

|                           |       |
|---------------------------|-------|
| Voltage switching DC min. | 3 V   |
| Switching voltage DC max. | 30 V  |
| Switching current min.    | 10 mA |
| Switching current max.    | 6 A   |

Diagnostics

|                       |        |
|-----------------------|--------|
| Status indication LED | yellow |
|-----------------------|--------|

Device protection | Electrical

|                                     |        |
|-------------------------------------|--------|
| Degree of protection (EN IEC 60529) | IP20   |
| Rated insulation voltage            | 50 V   |
| Rated surge voltage                 | 2,5 kV |

Mechanical data | Mounting data

|                 |          |
|-----------------|----------|
| Mounting method | inserted |
| Height          | 15 mm    |
| Width           | 5 mm     |
| Depth           | 28 mm    |

Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -25 °C |
| Operating temperature max. | 50 °C  |