

## EUROCARD HOLDER

SKP 32/2-F(b+z)-FK

Spring clamp terminals  
32-pole F (EN 60603)  
Row b, z  
250 V AC



With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.

The D2 size is for a card without a front plate.

To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

## 제품 링크

### 일러스트

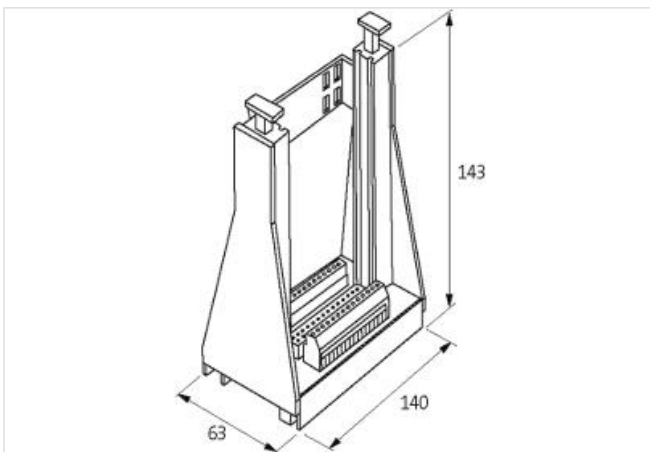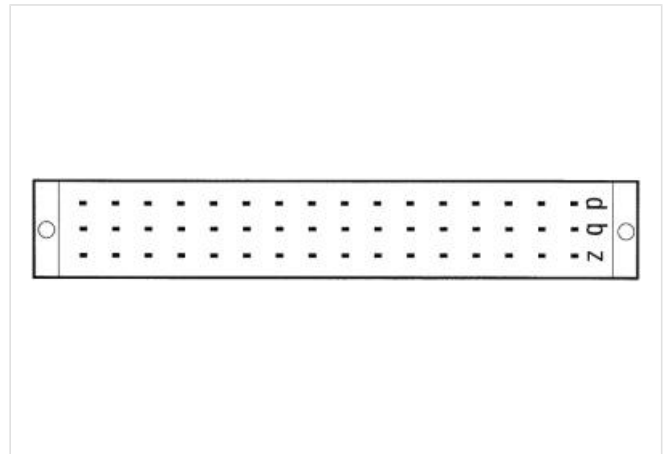

실제 제품은 이미지와 다를 수 있습니다.



### 제품자료

|            |          |
|------------|----------|
| ECLASS-6.0 | 27260710 |
| ECLASS-6.1 | 27260704 |

|             |               |
|-------------|---------------|
| ECLASS-7.0  | 27440402      |
| ECLASS-8.0  | 27440402      |
| ECLASS-9.0  | 27460201      |
| ECLASS-10.1 | 27440402      |
| ECLASS-11.1 | 27460201      |
| ECLASS-12.0 | 27460201      |
| ETIM-5.0    | EC002780      |
| GTIN        | 4048879038638 |
| 세번부호        | 85366990      |
| 포장단위        | 1             |

Electrical data | Supply

|                        |       |
|------------------------|-------|
| Operating voltage AC   | 250 V |
| Operating current max. | 4 A   |

Installation

|                                     |                   |
|-------------------------------------|-------------------|
| Connection cross-section solid max. | 4 mm <sup>2</sup> |
|-------------------------------------|-------------------|

Installation | Pin assignment

|              |    |
|--------------|----|
| No. of poles | 32 |
|--------------|----|

Device protection | Electrical

|                                   |   |
|-----------------------------------|---|
| Overvoltage category (EN 60664-1) | I |
|-----------------------------------|---|

Device protection | Media

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

Mechanical data

|                          |              |
|--------------------------|--------------|
| Type of socket connector | F (EN 60603) |
|--------------------------|--------------|

Mechanical data | Material data

|                  |         |
|------------------|---------|
| Material housing | Plastic |
|------------------|---------|

Mechanical data | Mounting data

|                            |                           |
|----------------------------|---------------------------|
| Mounting method            | screwed, geschnappt       |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height                     | 63 mm                     |
| Width                      | 137 mm                    |
| Depth                      | 170 mm                    |