



EUROCARD HOLDER

SKP 24/7-M-FK

Spring clamp terminals
24-, 7-pole M (EN 60603)
Row z, b, d
With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.
The D2 size is for a card without a front plate.
To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

제품 링크

일러스트

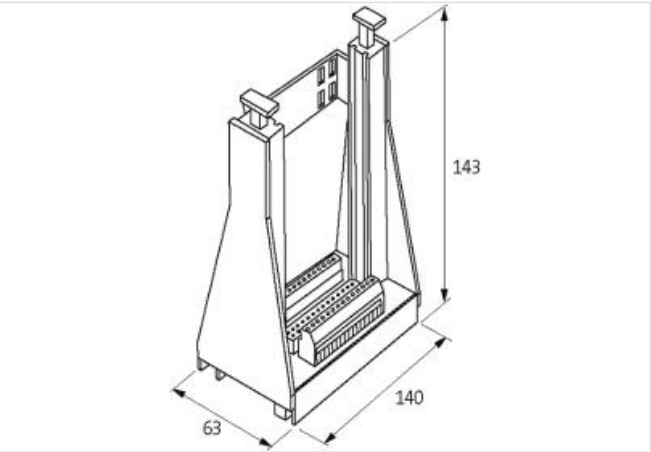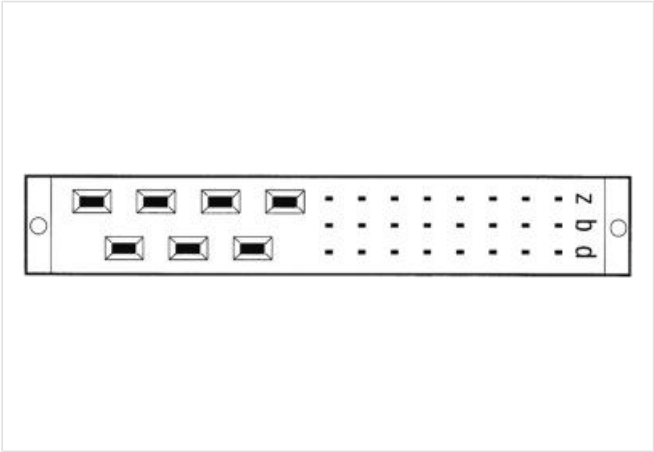

실제 제품은 이미지와 다를 수 있습니다.



Side 1	
Operating voltage AC	500 V
Operating current max.	4 A
No. of poles	7

Side 2

Operating voltage AC	250 V
Operating current max.	15 A
No. of poles	24

제품자료

ECLASS-6.0	27260710
ECLASS-6.1	27260704
ECLASS-7.0	27440402
ECLASS-8.0	27440402
ECLASS-9.0	27460201
ECLASS-10.1	27440402
ECLASS-11.1	27460201
ECLASS-12.0	27460201
ETIM-5.0	EC002780
GTIN	4048879038607
세번부호	85366990
포장단위	1

Installation

Connection cross-section solid max.	4 mm ²
-------------------------------------	-------------------

Installation | Pin assignment

No. of poles	24 + 7
--------------	--------

Device protection | Electrical

Overvoltage category (EN 60664-1)	I
-----------------------------------	---

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data

Type of socket connector	M (EN 60603)
--------------------------	--------------

Mechanical data | Material data

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	137 mm
Depth	170 mm