

MODLINK MSVD CABINET POWER OUTLETS

Denmark 250V AC / 13 A, spring clamp terminals


Denmark (white)
Spring clamp terminals

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

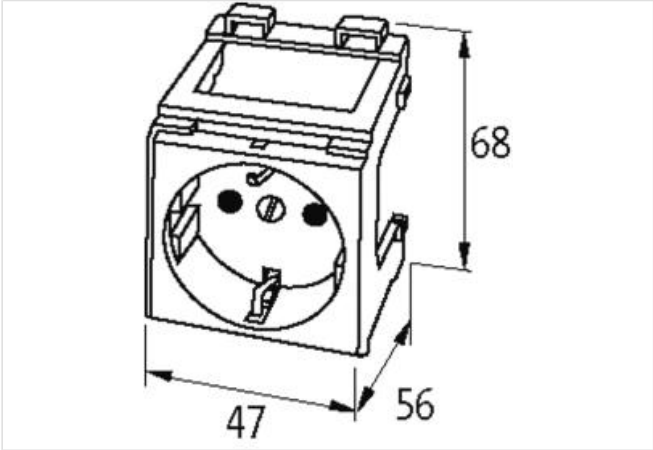

제품자료	
ECLASS-6.0	27143423
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC002625
GTIN	4048879031240
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	250 V
Operating current	13 A
Installation	
Connection cross section max.	2,5 mm²
AWG number	14
Installation Connection	
Connection	Spring clamp plug-in terminals
Mechanical data Mounting data	

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	68 mm
Width	47 mm
Depth	56 mm