

CHINA SOCKET MODULE


China (white)
Screw terminals

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

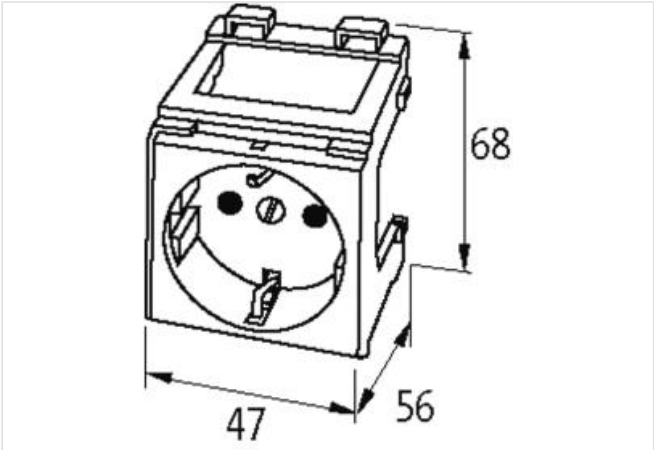

제품자료	
ECLASS-6.0	27143423
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
GTIN	4048879031196
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	250 V
Operating current	10 A
Installation	
Connection cross section max.	4 mm²
AWG number	12
Installation Connection	
Connection	Screw terminals SK
Mechanical data Mounting data	
Mounting method	geschnappt

Suitable for mounting type	mounting rail, (EN 60715)
Height	68 mm
Width	47 mm
Depth	57 mm