

MSDD pass-through RJ45 CAT5e femal/femal, design black




Neutral lid without logo



Pass-through

1 × RJ45, 8-pole CAT5e (female/female)

제품 링크

일러스트

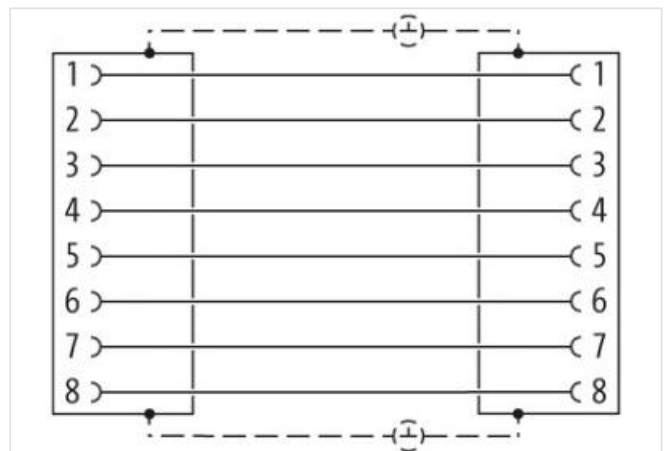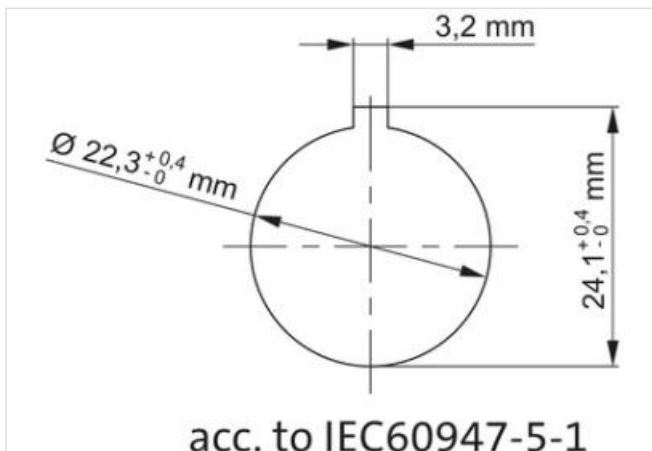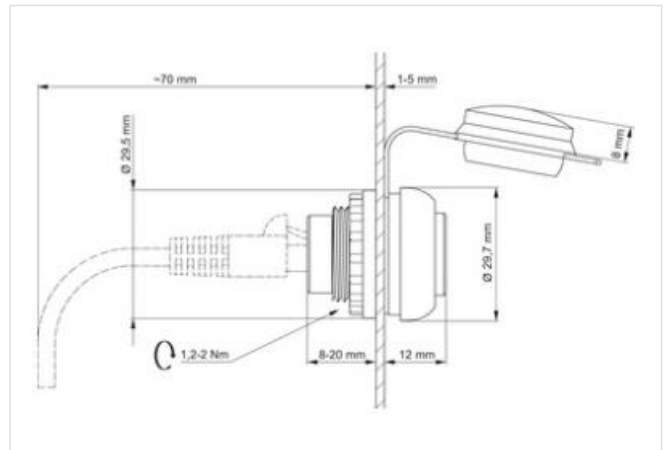

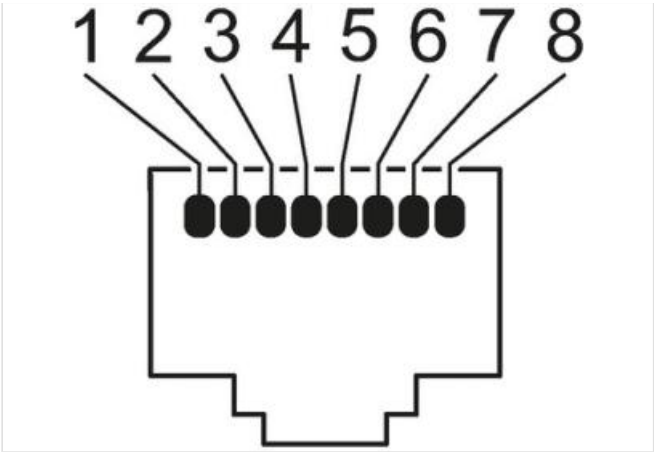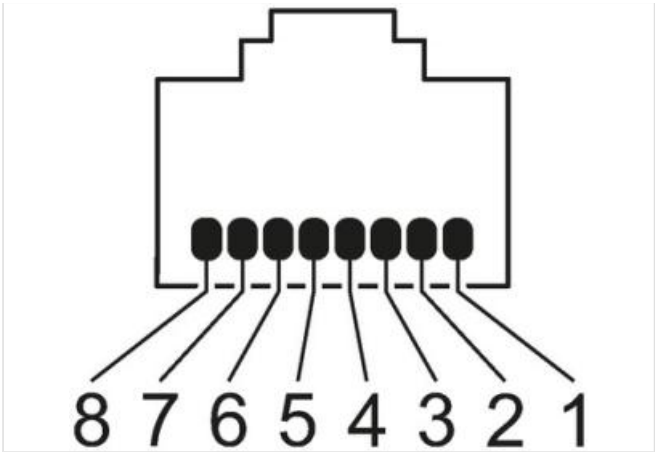

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
GTIN	4065909035931
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	24 V
Operating voltage DC	24 V
Operating current max.	1,5 A
Installation Connection	
Family construction form	RJ46
Gender	female
Gender Rear	female
Cable category min.	Cat5e
Device protection	
Shielded	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state
Device protection Mechanical	
Mechanical endurance	750 Cycles
Mechanical data Mounting data	
Diameter cutout	22,5 mm

Diameter	29,5 mm
Mounting depth	70 mm
Depth	20 mm
Approvals	
UL 50E	yes