

MSDD pass-through USB 3.0 form A, 0.6 m cable, design black




Neutral lid without logo



Pass-through

1 × USB 3.0 (female/male/0.6 m cable) form A

제품 링크

일러스트

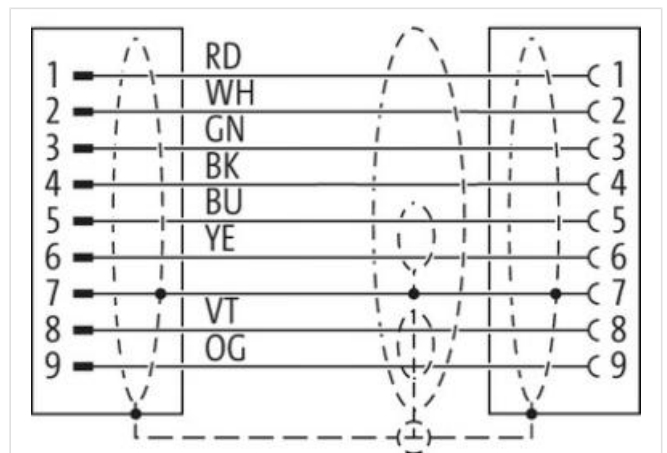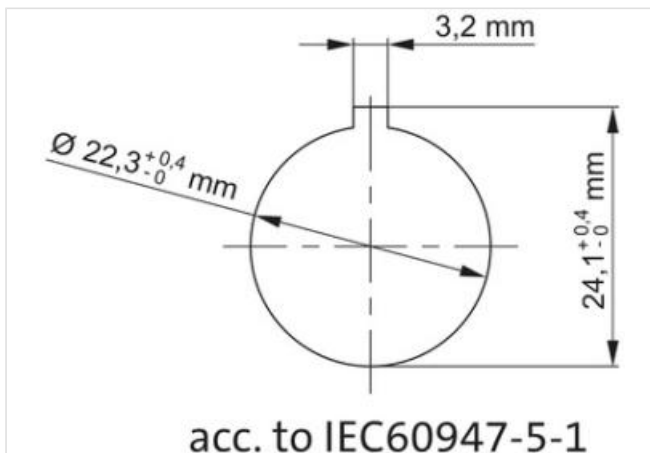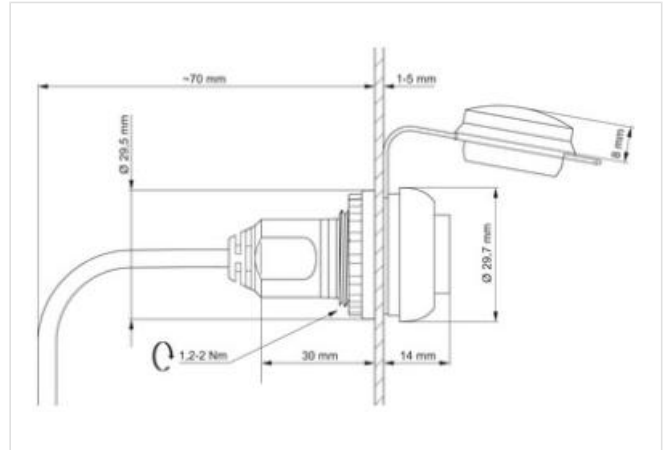

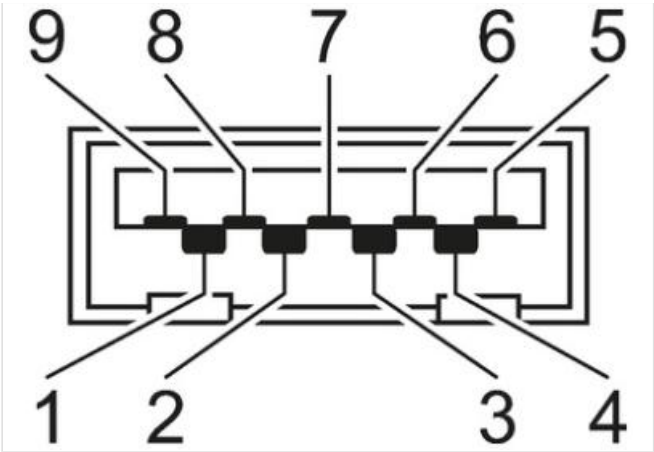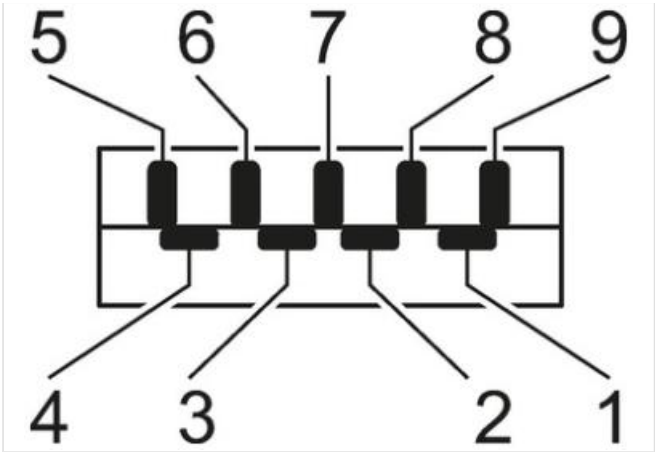

실제 제품은 이미지와 다를 수 있습니다.



제품자료

ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
GTIN	4065909037263
세번부호	85444290
포장단위	1

Electrical data | Supply

Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA

Industrial communication

USB specification	3.0
-------------------	-----

Device protection

Shielded	yes
----------	-----

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state

Device protection | Mechanical

Mechanical endurance	1500 Cycles
----------------------	-------------

Mechanical data | Mounting data

Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	30 mm

UL 50E

이 데이터 시트에 포함된 정보는 최대한의 주의로 작성되었습니다.
2024-05-05