

MSDD pass-through USB 3.0 form A, 2.0 m cable, design black




Neutral lid without logo



Pass-through

1 × USB 3.0 (female/male/2.0 m cable) form A

제품 링크

일러스트

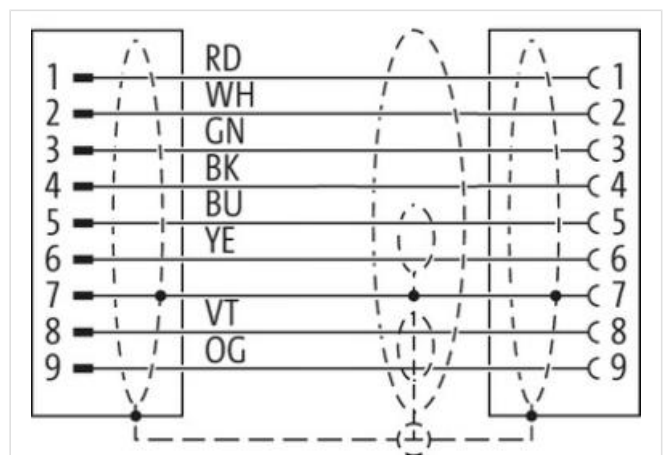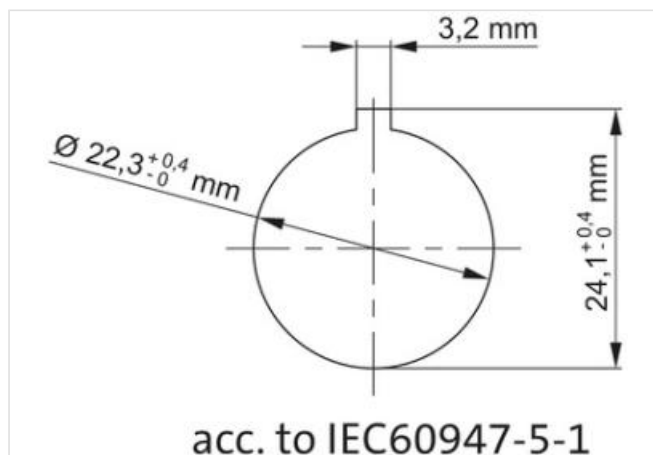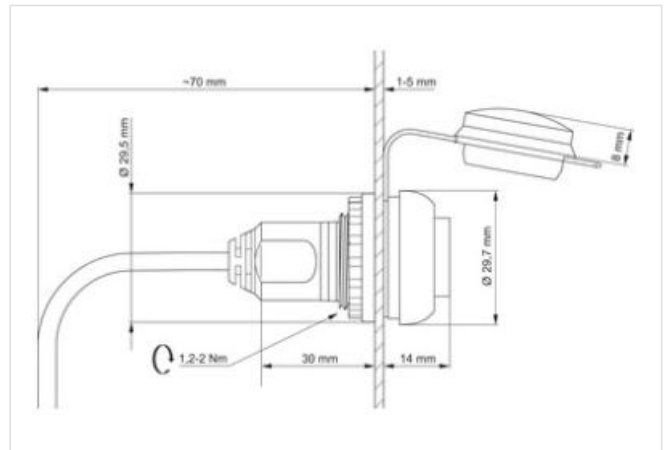

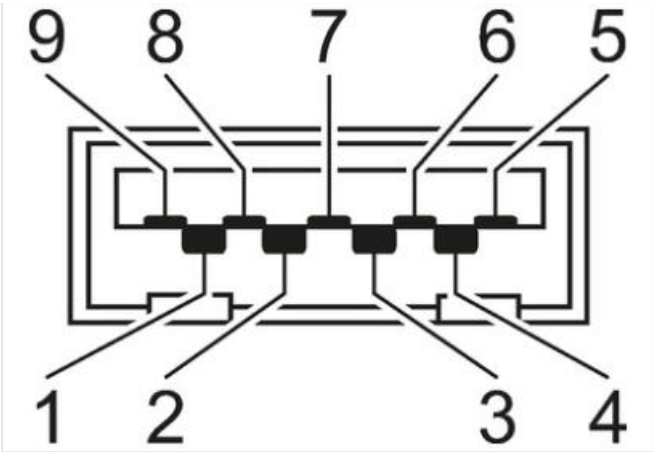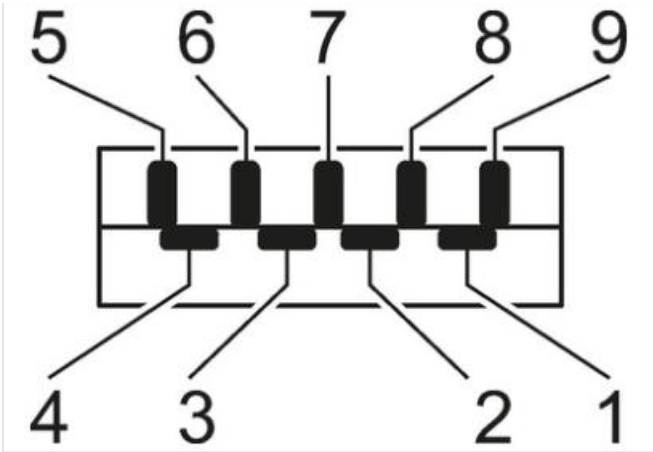

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
GTIN	4065909037294
세번부호	85444290
포장단위	1
Electrical data Supply	
Operating voltage AC	5 V
Operating voltage DC	5 V
Operating current max.	900 mA
Industrial communication	
USB specification	3.0
Device protection	
Shielded	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x
Additional condition protection degree	inserted, in closed state
Device protection Mechanical	
Mechanical endurance	1500 Cycles
Mechanical data Mounting data	
Diameter cutout	22,5 mm
Diameter	29,5 mm
Mounting depth	70 mm
Depth	30 mm

UL 50E

yes