

AIDA PUSH PULL COUPLING HAN24


with power (5 pole) spring clamp + RJ45 fem/fem

with RJ45 and energy
1 × RJ45, 8-pole metal, CAT5e (female/female)
Combicon Power/spring clamp terminal, Push Pull
Size 24

제품 링크

일러스트



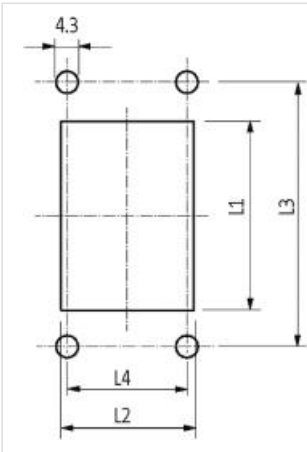

Size		6	24
Wall cut-out	L1	52	112
	L2	35	35
Distance of holes	L3	70	130
	L4	32	32

실제 제품은 이미지와 다를 수 있습니다.



제품자료

ECLASS-6.0	27143423
ECLASS-6.1	27143423
ECLASS-7.0	27449001
ECLASS-8.0	27449001
ECLASS-9.0	27440321
ECLASS-10.1	27440321
ECLASS-11.1	27440321
ECLASS-12.0	27440321
ETIM-5.0	EC002625
GTIN	4048879031165
세번부호	85366990
포장단위	1

Device protection | Electrical

Degree of protection (EN IEC 60529) IP65

Mechanical data | Material data

Material housing PA

Mechanical data | Mounting data

Height	146 mm
Width	58 mm
Depth	65 mm

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	70 °C