


MODLIGHT70 CONNECTION MODULE 8 POLE M12 SIDE EXIT

Product discontinued

제품 링크

일러스트

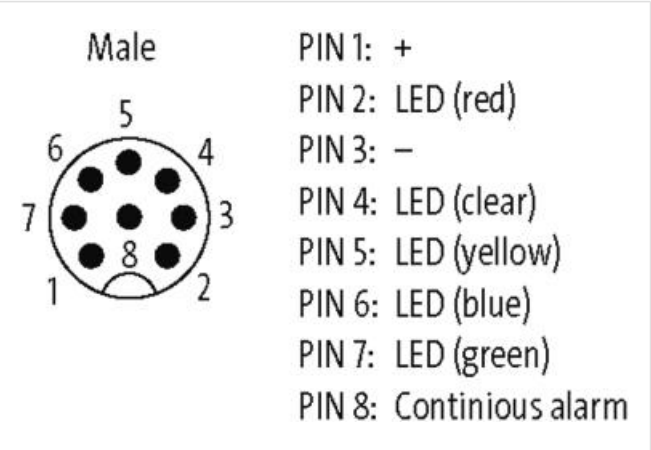

실제 제품은 이미지와 다를 수 있습니다.

제품자료	
ECLASS-6.0	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ETIM-5.0	EC001155
GTIN	4048879030823
세번부호	85319000
포장단위	1
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Height	190 mm
Width	70 mm
Depth	70 mm
Environmental characteristics Climatic	
Operating temperature min.	-30 °C
Operating temperature max.	60 °C
Connection type 1	
Family construction form	M12
Gender	male

Coding	A
No. of poles	8
PIN 1	+
PIN 2	LED RD
PIN 3	-
PIN 4	LED CL
PIN 5	LED YE
PIN 6	LED BU
PIN 7	LED GN
PIN 8	Continuous tone