


Modlight70 Pro connecting modul 5 pole M12

downward, Input 24VDC

Basic
with M12 connection
Outlet on the bottom
Connection cables are in the online shop under "Connection Technology".

제품 링크

일러스트

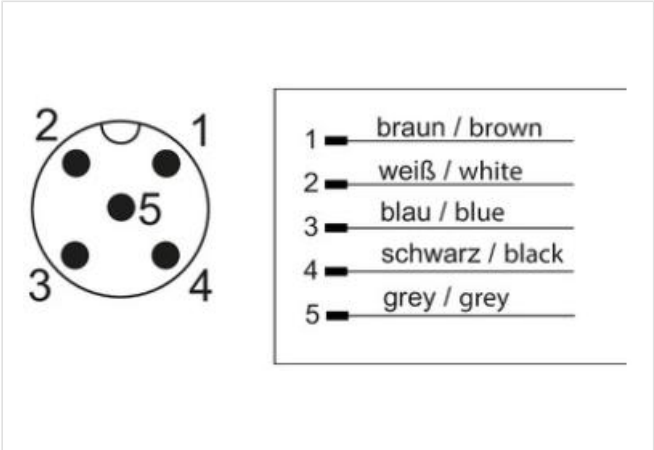

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
GTIN	4048879758888
세번부호	85319000
포장단위	1
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65

Additional condition protection degree inserted, locked

Mechanical data | Material data

Color housing	black
Material housing	Plastic

Mechanical data | Mounting data

Height	140 mm
Width	70 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	60 °C

Connection type 1

Mounting method bayonet-locking