

Modlight70 Pro connecting modul 8 pole M12

side, Input 24VDC


Basic
Outlet on the side
with M12 connection
Connection cables are in the online shop under "Connection Technology".

제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

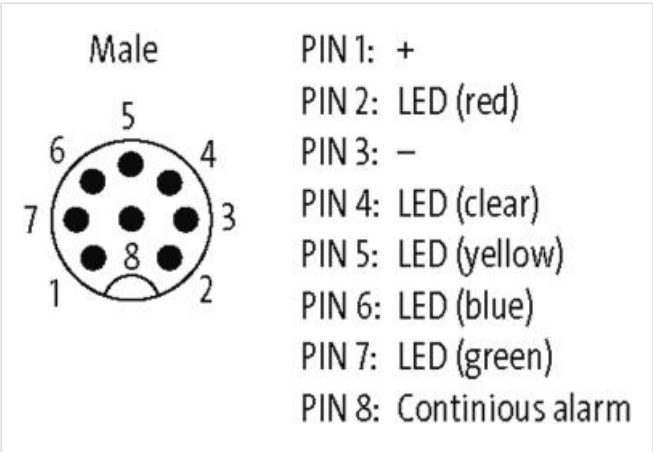

제품자료	
ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
GTIN	4048879758895
세번부호	85319000
포장단위	1
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65

Additional condition protection degree inserted, locked

Mechanical data | Material data

Color housing	black
Material housing	Plastic

Mechanical data | Mounting data

Height	122 mm
Width	88 mm
Depth	70 mm

Environmental characteristics | Climatic

Operating temperature min.	-30 °C
Operating temperature max.	60 °C

Connection type 2

Family construction form	M12
Gender	male
Coding	A
No. of poles	8
PIN 1	24 V DC / 0 V
PIN 2	LED-Modul RD
PIN 3	0 V / 24 V DC
PIN 4	LED-Modul CL
PIN 5	LED-Modul YE
PIN 6	LED-Modul BU
PIN 7	LED-Modul GN
PIN 8	Buzzer
Mounting method	bayonet-locking