

Modlight70 Pro connecting modul 8 pole M12

side, with magnet base

Basic
with M12 connection
with magnet base
M12 (8-pole), sideways
Connection cables are in the online shop under "Connection Technology".


제품 링크

일러스트



실제 제품은 이미지와 다를 수 있습니다.

Male

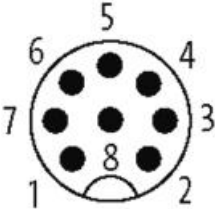

PIN 1: +
PIN 2: LED (red)
PIN 3: -
PIN 4: LED (clear)
PIN 5: LED (yellow)
PIN 6: LED (blue)
PIN 7: LED (green)
PIN 8: Continious alarm



제품자료	
ECLASS-6.0	27371232
ECLASS-6.1	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ECLASS-10.1	27371232
ECLASS-11.1	27371232
ECLASS-12.0	27371232
ETIM-5.0	EC001152
ETIM-6.0	EC001152
ETIM-7.0	EC001152
GTIN	4048879759601
세번부호	85319000
포장단위	1

Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V

Device protection Electrical	
--------------------------------	--

Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked
Mechanical data	
Adhesive force	290 N
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Height	135 mm
Width	88 mm
Depth	70 mm
Environmental characteristics Climatic	
Operating temperature min.	-30 °C
Operating temperature max.	60 °C
Connection type 2	
Family construction form	M12
Gender	male
Coding	A
No. of poles	8
PIN 1	24 V DC / 0 V
PIN 2	LED-Modul RD
PIN 3	0 V / 24 V DC
PIN 4	LED-Modul CL
PIN 5	LED-Modul YE
PIN 6	LED-Modul BU
PIN 7	LED-Modul GN
PIN 8	Buzzer
Mounting method	bayonet-locking