




M12 female 0° B-cod. screw terminal shielded

2-pol., max. 0.75mm², 6 - 8mm, shielded

Female straight
M12, 2-pole
B-coded
shielded
Screw terminals
Sealing range (cable Ø): 6...8 mm

제품 링크

일러스트

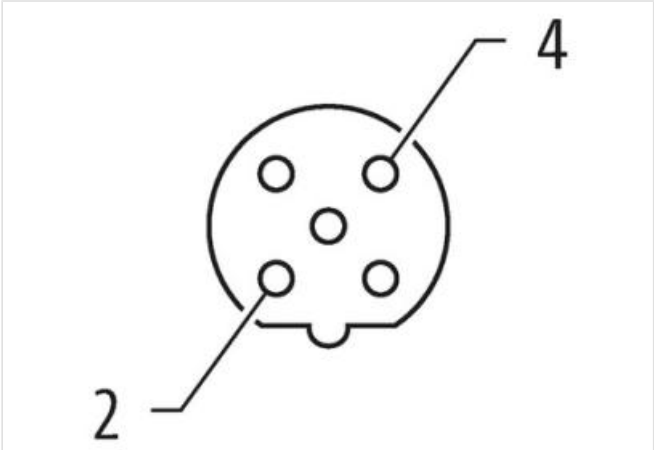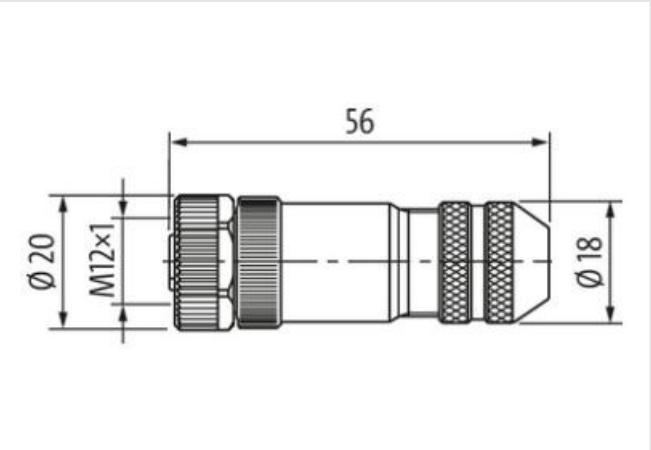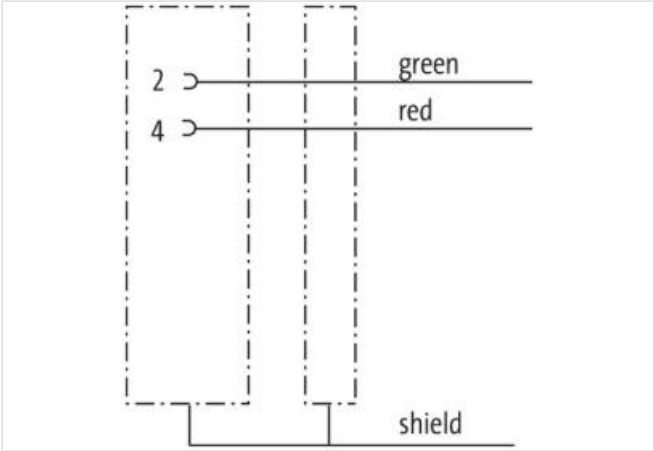

실제 제품은 이미지와 다를 수 있습니다.

Side 1	
Family construction form	M12
Degree of protection (EN IEC 60529)	IP67
제품자료	
ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ECLASS-10.1	27440102

ECLASS-11.1	27440102
ECLASS-12.0	27440116
ETIM-5.0	EC002635
GTIN	4048879198615
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage DC max.	60 V
Current operating per contact max.	4 A
Installation	
Connection cross section max.	0,75 mm²
Device protection Electrical	
Additional condition protection degree	inserted, screwed
Mechanical data Material data	
Coating housing	nickel plated
Material housing	Brass
Mechanical data Mounting data	
Clamping range min.	6 mm
Clamping range max.	8 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C