

SVS VALVE PLUG FORM B 10 MM FIELD-WIREABLE




230V LED+VDR PG9

Form B (10 mm)
230 V AC/DC $\pm 10\%$
LED and VDR
PG9

Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

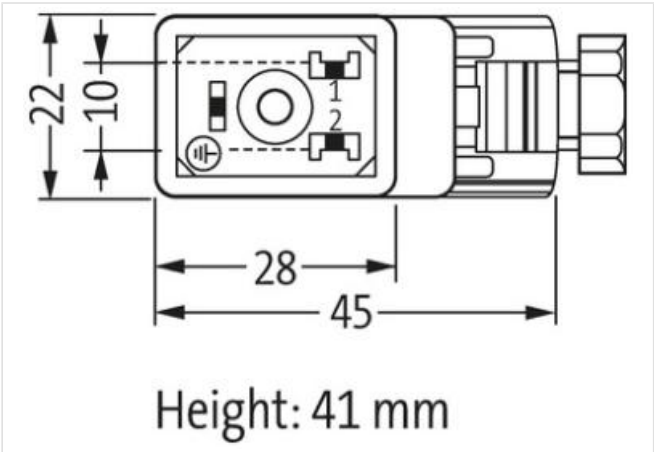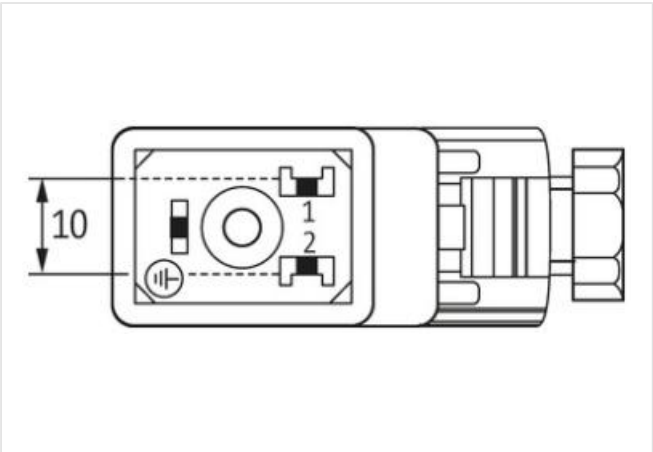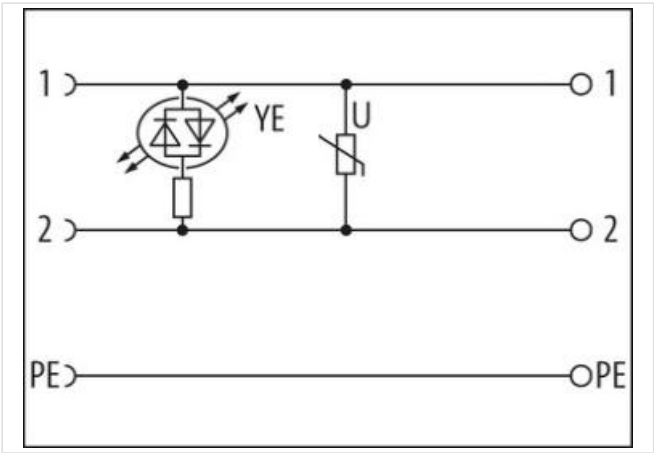

실제 제품은 이미지와 다를 수 있습니다.

Side 1	
Degree of protection (EN IEC 60529)	IP65
제품자료	
ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ETIM-5.0	EC002062
GTIN	4048879187251

세번부호	85366990
포장단위	1
Electrical data	
Capacity CX	15 ms
Holding power max.	100 W
Electrical data Supply	
Operating voltage AC	230 V
Operating voltage AC min.	207 V
Operating voltage AC max.	253 V
Operating voltage DC	230 V
Operating voltage DC min.	207 V
Operating voltage DC max.	253 V
Cut-off peak voltage max.	450 V
Current operating per contact max.	1 A
Current consumption max.	12 mA
Diagnostics	
Status indication LED	yellow
Installation	
Connection cross section max.	1,5 mm²
Installation Connection	
Tightening torque	0,4 Nm
Mounting set	M3
Device protection Electrical	
Additional condition protection degree	inserted, locked, with screw connection
Mechanical data Mounting data	
Mounting method	PG9
Clamping range min.	6 mm
Clamping range max.	8 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C