

M12-PANEL FEED THROUGH A-CODED

Control cabinet entry system

Male - female




M12, 5-pole

 
A-coded

shielded

제품 링크

일러스트

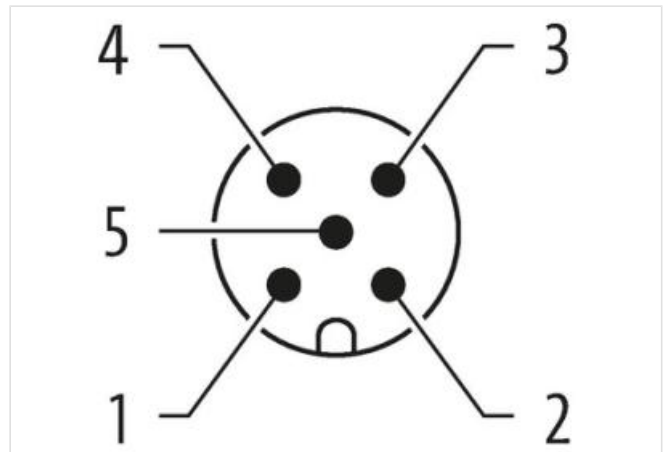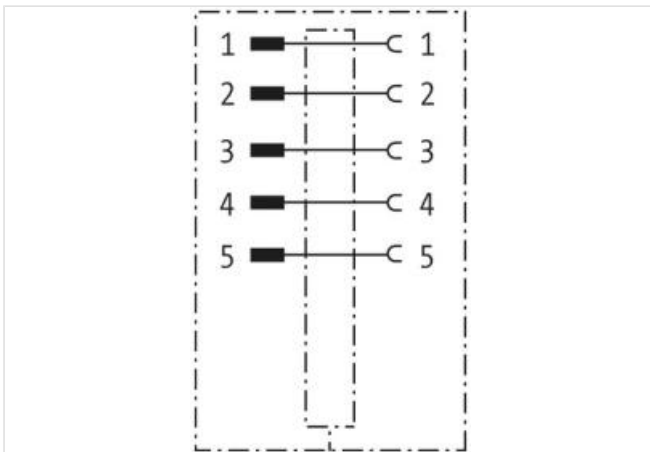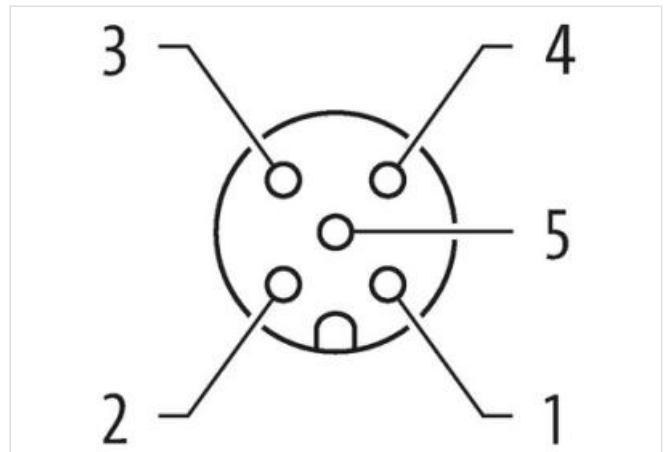



Family construction form	M12
Coding	A

Family construction form	M12
Coding	A

ECLASS-6.0	27143423
ECLASS-6.1	27279220
ECLASS-7.0	27440103
ECLASS-8.0	27440103
ECLASS-9.0	27440109
ECLASS-10.1	27440109
ECLASS-11.1	27440109
ECLASS-12.0	27440109
ETIM-5.0	EC001855
GTIN	4048879143233
세번부호	85366990
포장단위	1

Operating voltage AC max.	60 V
Operating voltage DC max.	60 V
Operating voltage AC (UL-listed)	30 V
Operating voltage DC (UL-listed)	30 V
Current operating per contact max.	4 A

Tightening torque	0,6 Nm
Mounting set	M16 x 1.5

Degree of protection (EN IEC 60529)	IP65, IP67
Protection NEMA	3, 4, 6P
Additional condition protection degree	inserted, screwed

Pollution Degree	2
Rated surge voltage	1,5 kV
Material group (IEC 60664-1)	I
Mechanical data Material data	
Coating housing	nickel plated
Material housing	Brass
Mechanical data Mounting data	
Mounting method	inserted, screwed, Shaking protection
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C
Approvals	
UL 50E	yes