
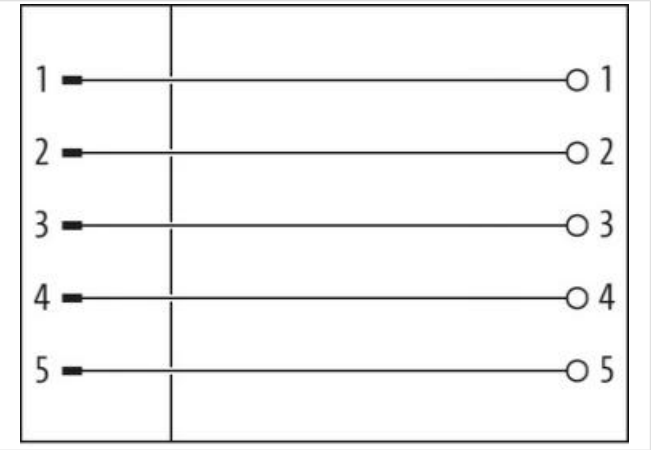


M12 MV insert shielded male snap / female


Insert - mobile housing
Female straight – male straight
M12, 5-pole
A-coded
Good chemical and oil resistance (oil resistance does not apply to use with PVC cable)
The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

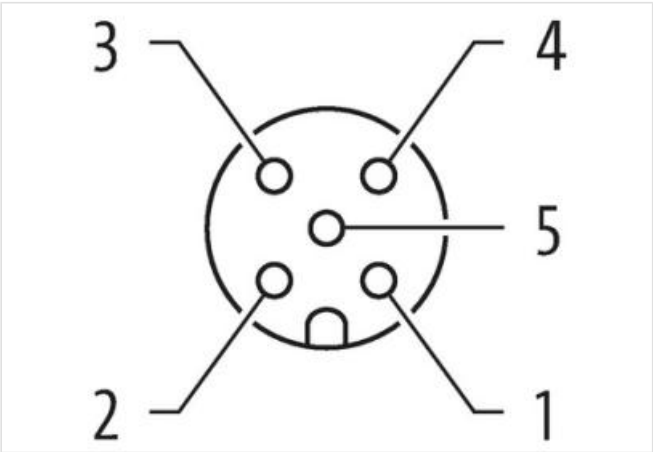

실제 제품은 이미지와 다를 수 있습니다.

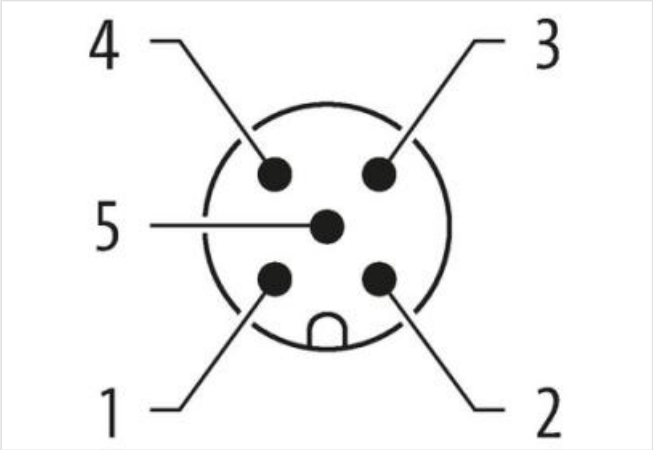

Side 1

Family construction form	M12
Coding	A

Side 2

Family construction form	M12
Coding	A

제품자료

ECLASS-6.0	27260702
ECLASS-6.1	27279221
ECLASS-7.0	27440104

ECLASS-8.0	27440104
ECLASS-9.0	27440106
ECLASS-10.1	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
ETIM-5.0	EC001855
GTIN	4048879562812
세번부호	85366990
포장단위	1

Electrical data | Supply

Operating voltage AC	49 V
Operating voltage DC	49 V
Current operating per contact max.	4 A

Installation | Connection

Tightening torque	0,6 Nm
Mounting set	M12 x 1

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP65, IP67
Additional condition protection degree	inserted, screwed
Rated surge voltage	1,5 kV

Mechanical data | Material data

Coating housing	nickel plated
Material gasket	FKM
Material housing	Brass

Mechanical data | Mounting data

Mounting method	inserted, screwed, Shaking protection
-----------------	---------------------------------------

Environmental characteristics | Climatic

Operating temperature min.	-25 °C
Operating temperature max.	85 °C