

T-Coupler M12 female/M12 male+ cable+M12 male A-cod

8-pol. / 4-pol. + 3-pol.

T-coupler (Slim Line)

Male straight – female/male straight

M12 – M12, 3-pole

Connection cable 0.15 m




Distribution function (NO)


Plastic housings with good resistance against chemicals and oils.

The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

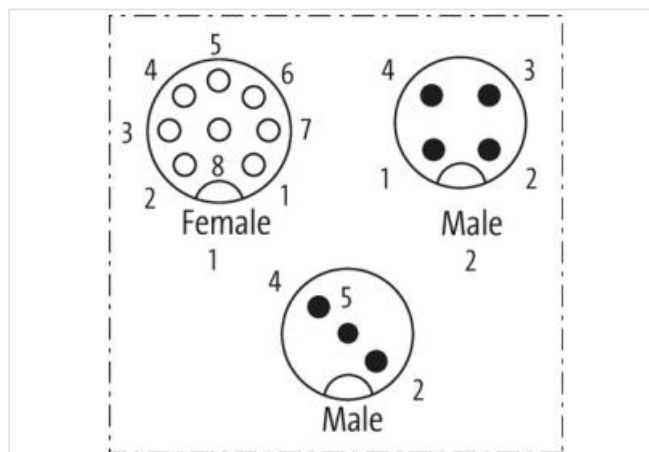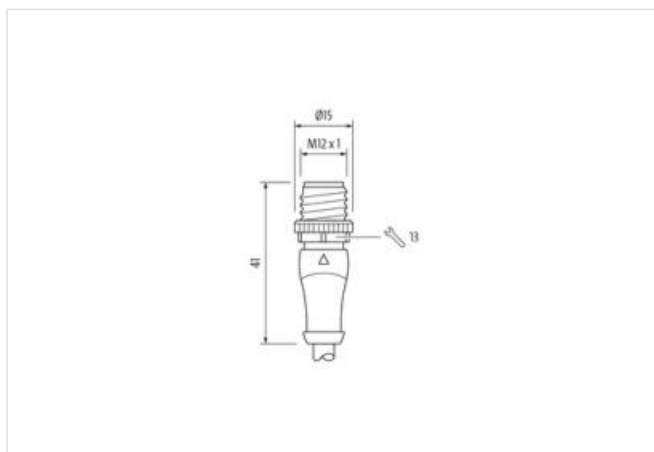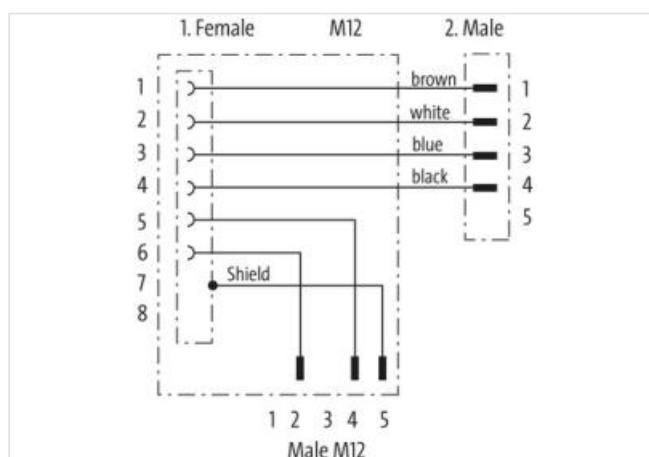

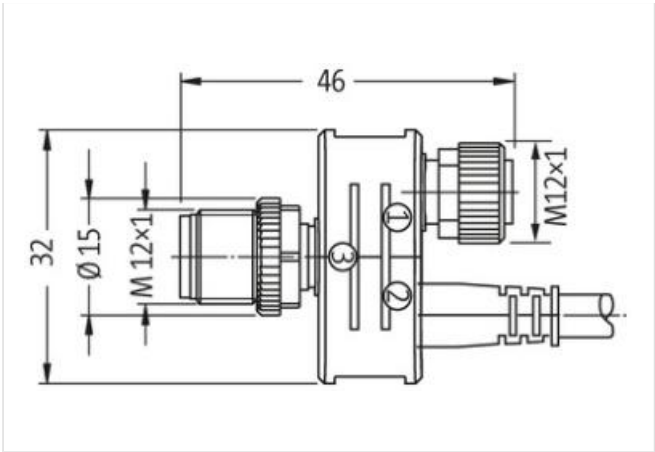

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27143423
ECLASS-6.1	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440106
ECLASS-10.1	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
ETIM-5.0	EC002635
GTIN	4048879142564
세번부호	85444290
포장단위	1

Electrical data Supply	
Operating voltage AC max.	30 V
Operating voltage DC max.	30 V

Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C

Important installation notes	
Note on strain relief	Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.
Note on bending radius	Attention: Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces.