

MODL.VARIO insert for fixed housing type B

8-pole M12, male, shielded

Insert - stationary housing

Male straight – female straight

M12, 8-pole




A-coded


Good chemical and oil resistance (oil resistance does not apply to use with PVC cable)

The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

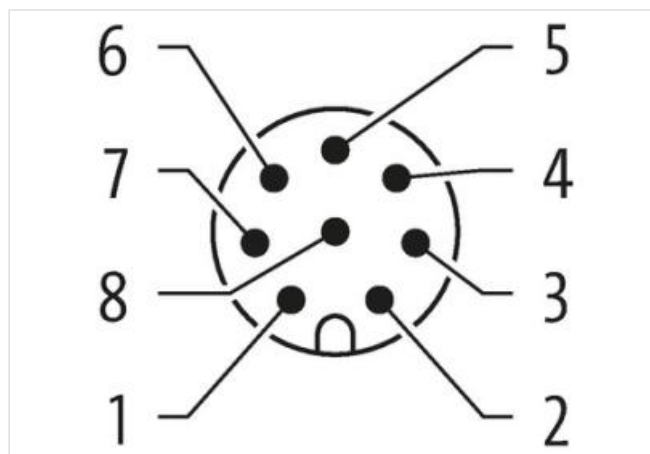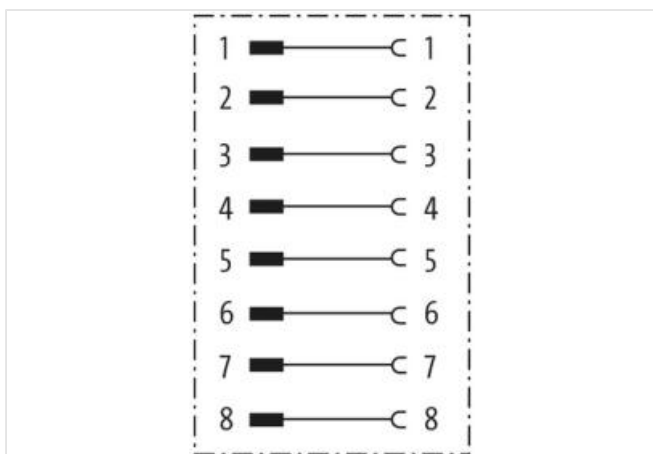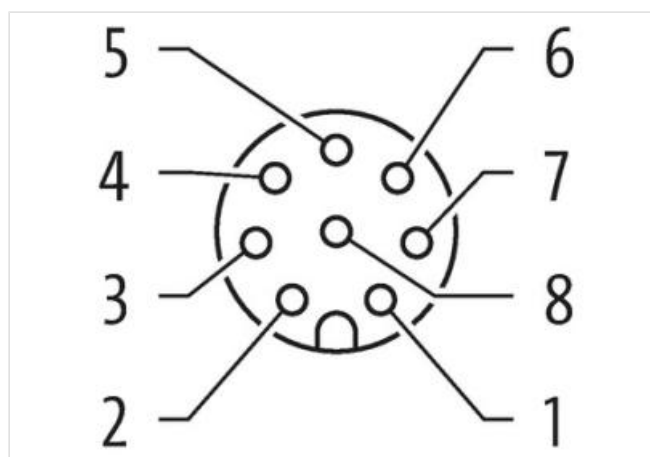

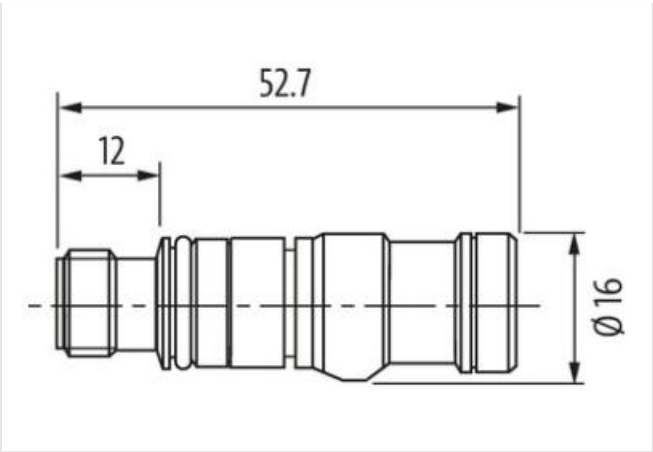

실제 제품은 이미지와 다를 수 있습니다.

Side 1	
Family construction form	M12
Coding	A
Side 2	
Family construction form	M12
Coding	A
제품자료	
ECLASS-6.0	27279221
ECLASS-6.1	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440106
ECLASS-10.1	27440106
ECLASS-11.1	27440106
ECLASS-12.0	27440106
ETIM-5.0	EC001855
GTIN	4048879576536
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC max.	30 V
Operating voltage DC max.	30 V
Current operating per contact max.	2 A
Installation Connection	
Tightening torque	0,6 Nm
Mounting set	M12 x 1
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65, IP67
Additional condition protection degree	inserted, screwed
Rated insulation voltage	800 V
Rated surge voltage	0,8 kV
Mechanical data Material data	
Coating housing	nickel plated
Material gasket	FKM
Material housing	Brass
Mechanical data Mounting data	

Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	85 °C