




7/8" female 0° screw terminal

5-pol., max. 1,5mm², 10 - 12mm

Female straight  
7/8" (5-pole)  
Screw terminals  
Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

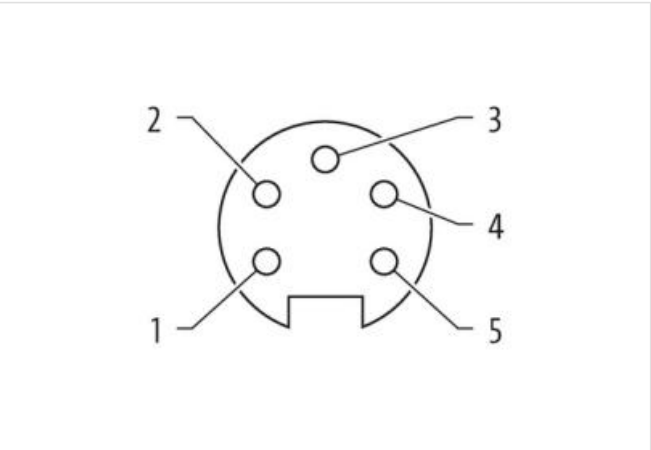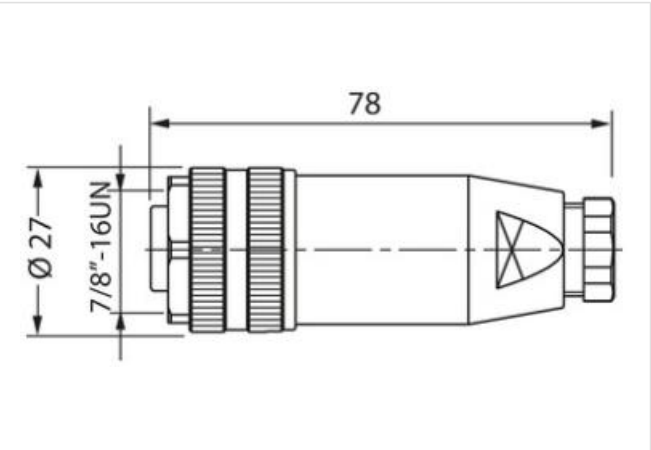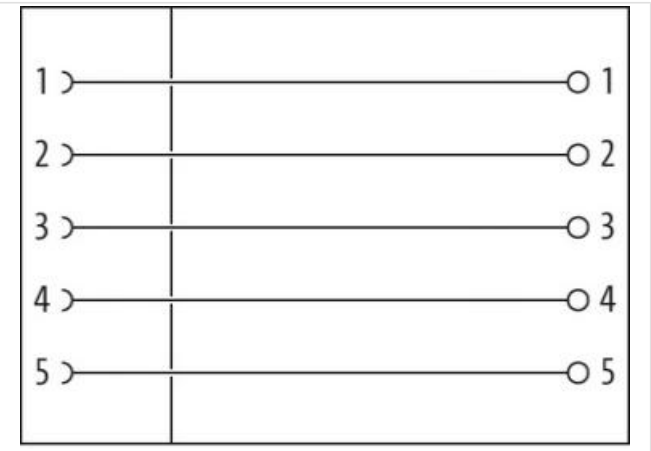

실제 제품은 이미지와 다를 수 있습니다.



|                   |          |
|-------------------|----------|
| Side 1            |          |
| Tightening torque | 1,5 Nm   |
| Thread            | 7/8"     |
| 제품자료              |          |
| ECLASS-6.0        | 27279218 |

|                                          |                                                                                                                                                       |
|------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------|
| ECLASS-6.1                               | 27260702                                                                                                                                              |
| ECLASS-7.0                               | 27440102                                                                                                                                              |
| ECLASS-8.0                               | 27440102                                                                                                                                              |
| ECLASS-9.0                               | 27440116                                                                                                                                              |
| ECLASS-10.1                              | 27440102                                                                                                                                              |
| ECLASS-11.1                              | 27440102                                                                                                                                              |
| ECLASS-12.0                              | 27440116                                                                                                                                              |
| ETIM-5.0                                 | EC002635                                                                                                                                              |
| GTIN                                     | 4048879134712                                                                                                                                         |
| 세번부호                                     | 85366990                                                                                                                                              |
| 포장단위                                     | 1                                                                                                                                                     |
| Electrical data   Supply                 |                                                                                                                                                       |
| Operating voltage AC max.                | 250 V                                                                                                                                                 |
| Operating voltage DC max.                | 250 V                                                                                                                                                 |
| Current operating per contact max.       | 9 A                                                                                                                                                   |
| Installation                             |                                                                                                                                                       |
| Connection cross section max.            | 1,5 mm²                                                                                                                                               |
| Device protection   Electrical           |                                                                                                                                                       |
| Degree of protection (EN IEC 60529)      | IP67                                                                                                                                                  |
| Additional condition protection degree   | inserted, screwed                                                                                                                                     |
| Mechanical data   Material data          |                                                                                                                                                       |
| Coating locking                          | Nickeled                                                                                                                                              |
| Locking material                         | Zinc die-casting                                                                                                                                      |
| Mechanical data   Mounting data          |                                                                                                                                                       |
| Mounting method                          | inserted, screwed, Shaking protection                                                                                                                 |
| Clamping range min.                      | 10 mm                                                                                                                                                 |
| Clamping range max.                      | 12 mm                                                                                                                                                 |
| Environmental characteristics   Climatic |                                                                                                                                                       |
| Operating temperature min.               | -25 °C                                                                                                                                                |
| Operating temperature max.               | 85 °C                                                                                                                                                 |
| Important installation notes             |                                                                                                                                                       |
| Note on strain relief                    | Protect the connectors by suitable measures from mechanical loads, e.g. by the usage of cable ties.                                                   |
| Note on bending radius                   | <b>Attention:</b> Observe the permissible bending radii when laying cables, as the IP protection class can be endangered by excessive bending forces. |