


Wall bushing for push pull power

With spring-cage connection, flexible coding

Push Pull Power metal mounting frame
incl. contact insert with spring clamp connection
flexible coding
Suitable for rectangular mounting cut-out
with gasket
without fixing screws

제품 링크

일러스트

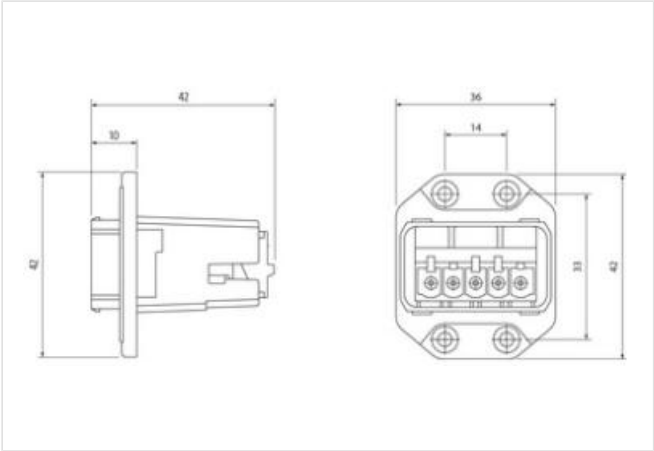

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ECLASS-10.1	27440210
ECLASS-11.1	27440210
ECLASS-12.0	27440210
ETIM-5.0	EC002635
GTIN	4048879900454
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage DC	24 V
Operating current	16 A
Installation	
Connection cross section min.	0,75 mm²
Connection cross section max.	2,5 mm²
AWG number min.	18

AWG number max.	13
Installation Connection	
Connection	Spring clamp terminals FK
Mating cycles min.	100
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65, IP67
Additional condition protection degree	inserted, screwed
Pollution Degree	2
Rated surge voltage	4 kV
Mechanical data Material data	
Coating housing	nickel plated
Combustibility class (UL94)	V-0
Material housing	Zinc die-casting
Mechanical data Mounting data	
Mounting method	5-pole, PPP
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	70 °C