


B6 female 6-pole, Push-in, 500 V, 16 A


E-Series  
B6  
Female  
6-pole  
Push-In terminals  
Technical data will be only guaranteed with Murrelektronik components.  
Please use wire end ferrule.

제품 링크

일러스트

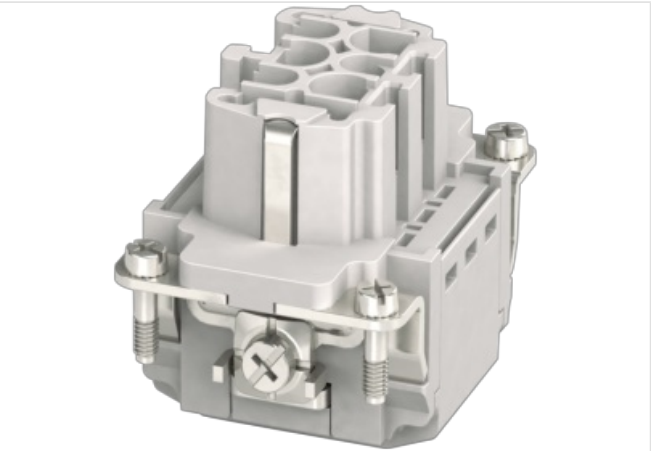

실제 제품은 이미지와 다를 수 있습니다.

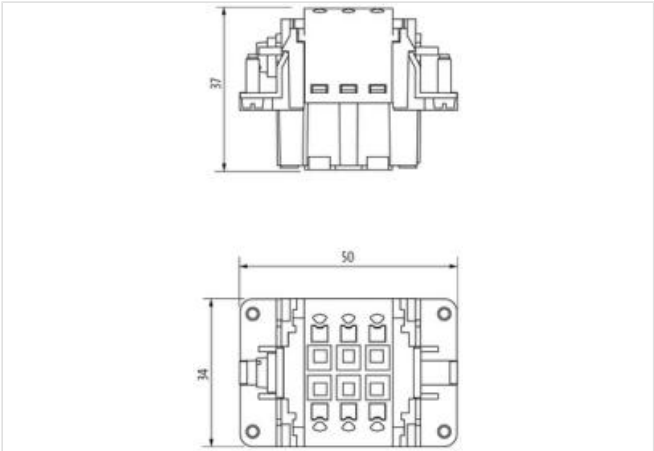

| 제품자료                          |               |
|-------------------------------|---------------|
| ECLASS-6.0                    | 27143424      |
| ECLASS-6.1                    | 27261204      |
| ECLASS-7.0                    | 27440205      |
| ECLASS-8.0                    | 27440205      |
| ECLASS-9.0                    | 27440205      |
| ECLASS-10.1                   | 27440205      |
| ECLASS-11.1                   | 27440205      |
| ECLASS-12.0                   | 27440205      |
| ETIM-5.0                      | EC000438      |
| GTIN                          | 4048879664455 |
| 세번부호                          | 85389099      |
| 포장단위                          | 1             |
| Electrical data   Supply      |               |
| Operating voltage AC          | 500 V         |
| Operating voltage DC          | 500 V         |
| Operating current             | 16 A          |
| Installation                  |               |
| Connection cross section min. | 0,14 mm²      |
| Connection cross section max. | 2,5 mm²       |

|                                          |                                |
|------------------------------------------|--------------------------------|
| AWG number min.                          | 26                             |
| AWG number max.                          | 14                             |
| Installation   Connection                |                                |
| Stripping length min.                    | 8 mm                           |
| Stripping length max.                    | 10 mm                          |
| Connection                               | Push-In spring clamp terminals |
| Gender                                   | female                         |
| Mating cycles min.                       | 500                            |
| Installation   Pin assignment            |                                |
| No. of poles                             | 6 + PE                         |
| Device protection   Electrical           |                                |
| Pollution Degree                         | 3                              |
| Rated surge voltage                      | 6 kV                           |
| Overvoltage category (EN 60950-1)        | III                            |
| Mechanical data   Material data          |                                |
| Coating contact                          | silver-plated                  |
| Combustibility class (UL94)              | V-0                            |
| Material contact                         | Brass                          |
| Material contact carrier                 | PC                             |
| Mechanical data   Mounting data          |                                |
| Size                                     | B6                             |
| Height                                   | 35,6 mm                        |
| Width                                    | 33,9 mm                        |
| Depth                                    | 50,4 mm                        |
| Environmental characteristics   Climatic |                                |
| Operating temperature min.               | -40 °C                         |
| Operating temperature max.               | 125 °C                         |
| Climatic category (EN IEC 60068-1)       | 40/125/10                      |