


Male module, 2-pole, axial screw t.

1000 V, 100 A

Male
2-pole
Axial screw connection
Technical data will be only guaranteed with Murrelektronik components.
Axial screw connection only for flexible wires
The clip 70MH-ZZ100-0000000 is needed (4×)

제품 링크

일러스트

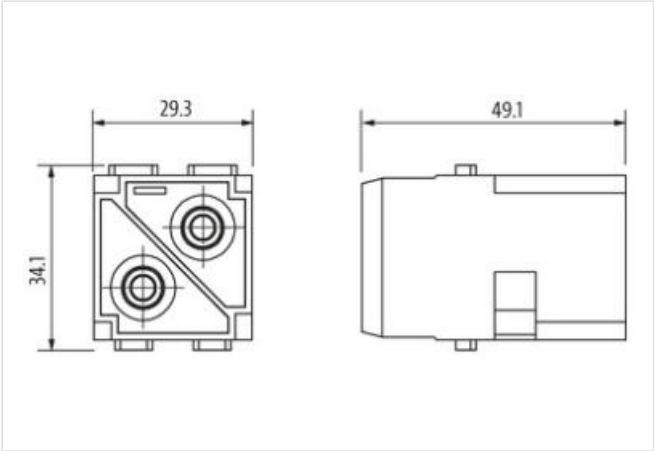

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27143424
ECLASS-6.1	27261204
ECLASS-7.0	27440204
ECLASS-8.0	27440204
ECLASS-9.0	27440217
ECLASS-10.1	27440217
ECLASS-11.1	27440217
ECLASS-12.0	27440217
ETIM-5.0	EC000438
GTIN	4048879675109
세번부호	85366990
포장단위	1
Electrical data Supply	
Operating voltage AC	1000 V
Operating voltage DC	1000 V
Operating current	100 A
Installation	
Connection cross section min.	10 mm²

Connection cross section max.	35 mm²
AWG number min.	8
AWG number max.	2
Installation Connection	
Stripping length	13 mm
Wire insulation diameter min.	11,4 mm
Connection information	Axial screw connection
Tightening torque	(10...16 mm²); 7 Nm (25 mm²); 8 Nm (35 mm²)
Tightening torque	6 Nm
Gender	male
Width across flats	SW4
Mating cycles min.	500
Installation Pin assignment	
No. of poles	2
Device protection Electrical	
Pollution Degree	3
Rated surge voltage	8 kV
Overvoltage category (EN 60950-1)	III
Mechanical data Material data	
Coating contact	silver-plated
Combustibility class (UL94)	V-0
Material housing	PC
Material contact	Brass
Mechanical data Mounting data	
Number of module slots	2
Height	49 mm
Width	34,1 mm
Depth	29,3 mm
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	125 °C