




M12 male 0° field-wireable

4-pole max. 0.75mm² 4-6mm

Customized printing and packaging  
Male straight  
M12, 4-pole  
Screw terminals  
Sealing range (cable Ø): 4...6 mm  
Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

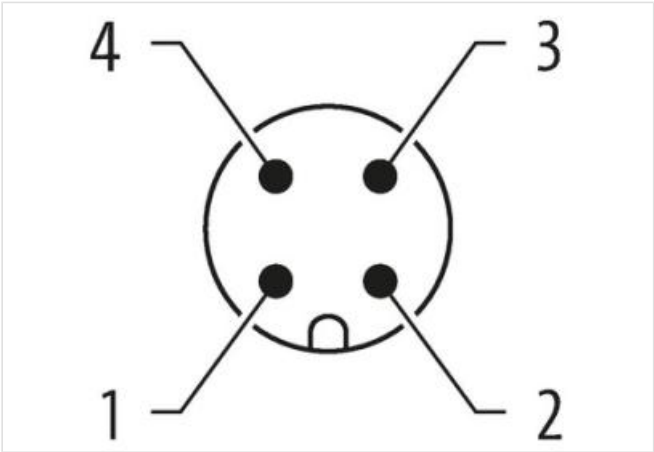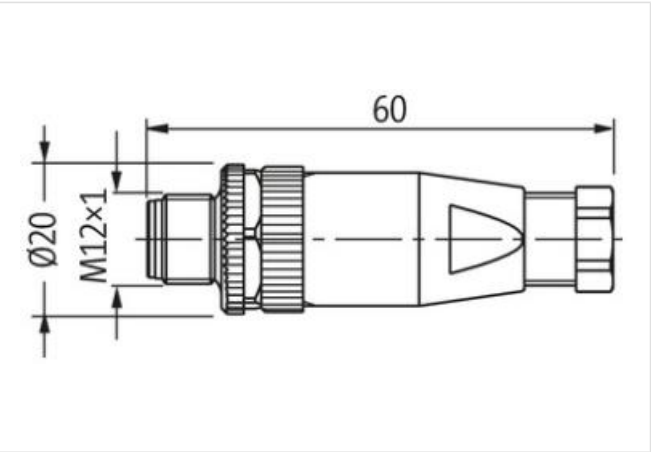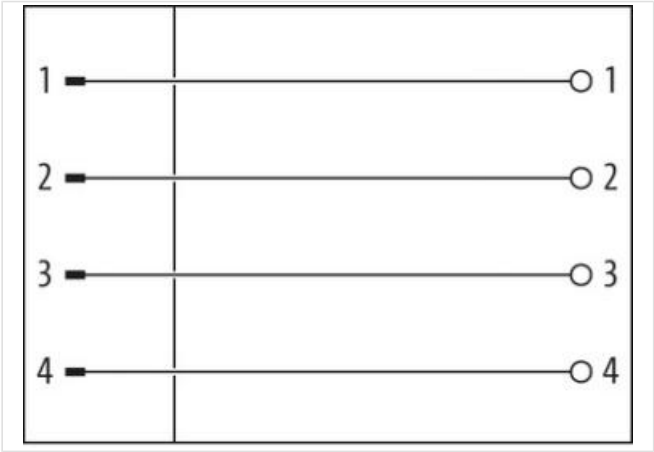

실제 제품은 이미지와 다를 수 있습니다.



|                          |              |
|--------------------------|--------------|
| Side 1                   |              |
| Family construction form | M12          |
| Coding                   | A            |
| Material contact         | Copper alloy |

|                                                 |                                       |
|-------------------------------------------------|---------------------------------------|
| No. of poles                                    | 4                                     |
| Degree of protection (EN IEC 60529)             | IP67                                  |
| <b>제품자료</b>                                     |                                       |
| ECLASS-6.0                                      | 27279221                              |
| ECLASS-7.0                                      | 27440104                              |
| ECLASS-8.0                                      | 27440104                              |
| ECLASS-9.0                                      | 27440102                              |
| ECLASS-10.1                                     | 27440102                              |
| ECLASS-11.1                                     | 27440102                              |
| ECLASS-12.0                                     | 27440116                              |
| ETIM-5.0                                        | EC001855                              |
| GTIN                                            | 4048879848688                         |
| 세번부호                                            | 85366990                              |
| 포장단위                                            | 10                                    |
| <b>Electrical data   Supply</b>                 |                                       |
| Operating voltage AC max.                       | 250 V                                 |
| Operating voltage DC max.                       | 250 V                                 |
| Current operating per contact max.              | 4 A                                   |
| Current operating per contact max. (URc.)       | 3 A                                   |
| <b>Diagnostics</b>                              |                                       |
| Status indication LED                           | no                                    |
| <b>Installation</b>                             |                                       |
| Connection cross section max.                   | 0,75 mm²                              |
| <b>Installation   Connection</b>                |                                       |
| Tightening torque                               | 0,6 Nm                                |
| Mounting set                                    | M12 x 1                               |
| Width across flats                              | SW18                                  |
| <b>Device protection   Electrical</b>           |                                       |
| Additional condition protection degree          | screwed, mounted                      |
| Pollution Degree                                | 3                                     |
| Rated surge voltage                             | 2,5 kV                                |
| Material group (IEC 60664-1)                    | III                                   |
| <b>Mechanical data   Material data</b>          |                                       |
| Coating contact                                 | Copper alloy                          |
| Coating of fitting                              | nickel plated                         |
| Material housing                                | PA                                    |
| Material screw connection                       | Zinc die-casting                      |
| <b>Mechanical data   Mounting data</b>          |                                       |
| Mounting method                                 | inserted, screwed, Shaking protection |
| Clamping range min.                             | 4 mm                                  |
| Clamping range max.                             | 6 mm                                  |
| <b>Environmental characteristics   Climatic</b> |                                       |
| Operating temperature min.                      | -40 °C                                |
| Operating temperature max.                      | 85 °C                                 |
| <b>Conformity</b>                               |                                       |
| Product standard                                | DIN EN 61076-2-101 (M12)              |