

EXACT12, 4XM12, 4 POLE

Conn.M12 8pole

4-way

4-pole (port 3+4)

5-pole (port 1+2)



M12 plug connection, 8-pole

with LED for digital PNP-signals 24 V DC


Plastic housings with good resistance against chemicals and oils.

제품 링크

일러스트

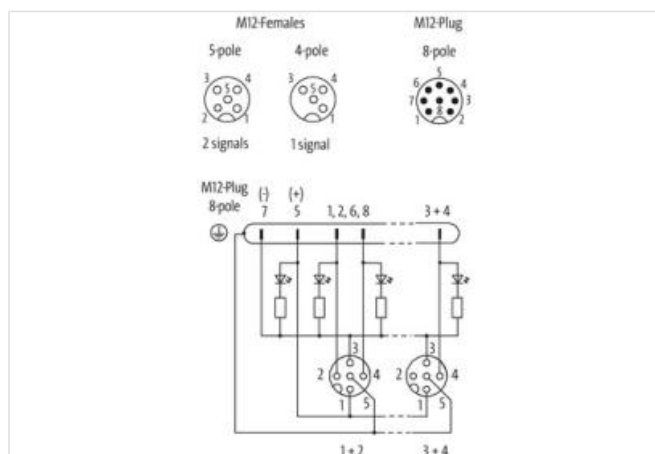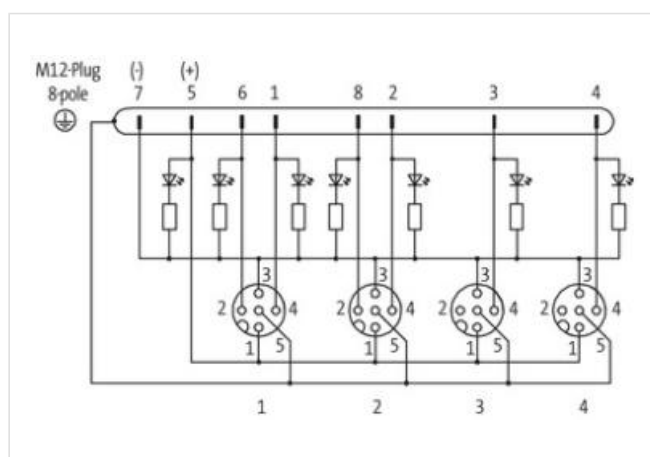

실제 제품은 이미지와 다를 수 있습니다.

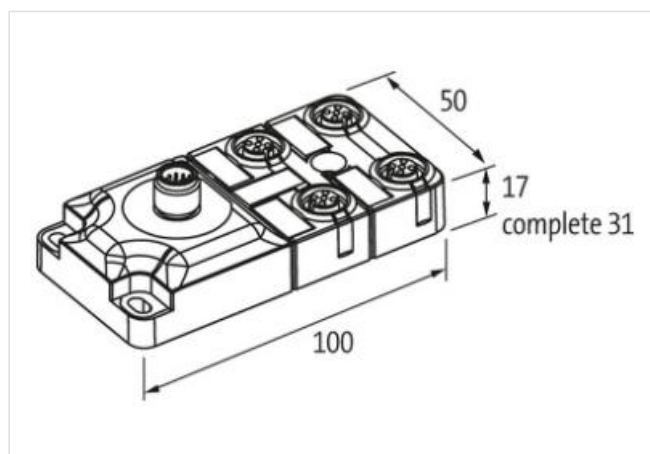

제품자료

ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219

ECLASS-8.0	27279219
ECLASS-9.0	27440111
ECLASS-10.1	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
GTIN	4048879323086
세번부호	85369010
포장단위	1
Electrical data Supply	
Operating voltage DC	24 V
Current operating per contact max.	2 A
Total current max.	2 A
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65, IP67
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C
Connection type 2	
Family construction form	M12
Gender	male
Color contact carrier	black
Coding	A
No. of poles	8
PIN 5	+
Family construction form	M8
Gender	female
Color contact carrier	black
Coding	A
No. of poles	4
PIN 1	+
PIN 2	n.c.
PIN 3	-
PIN 4	NO S 1