
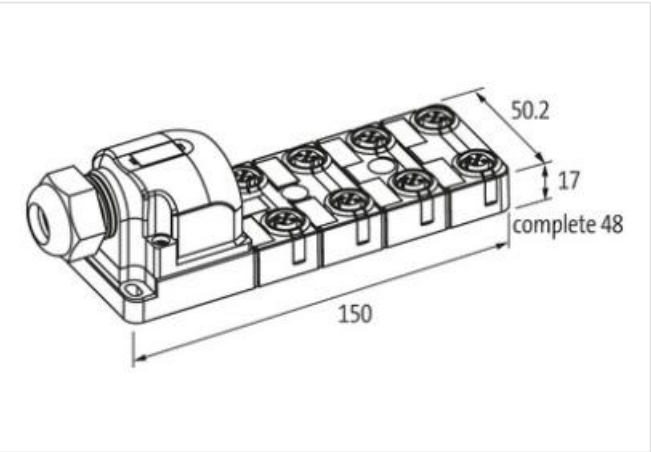


EXACT12, 8XM12, 4 POLE CAP, PLUG. SCREW-TERM.


8-way, 4-pole
Form PNP
Screw plug-in terminals
Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

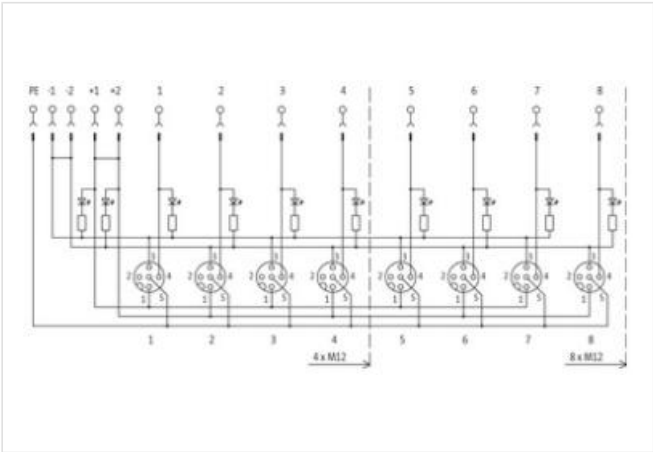

실제 제품은 이미지와 다를 수 있습니다.

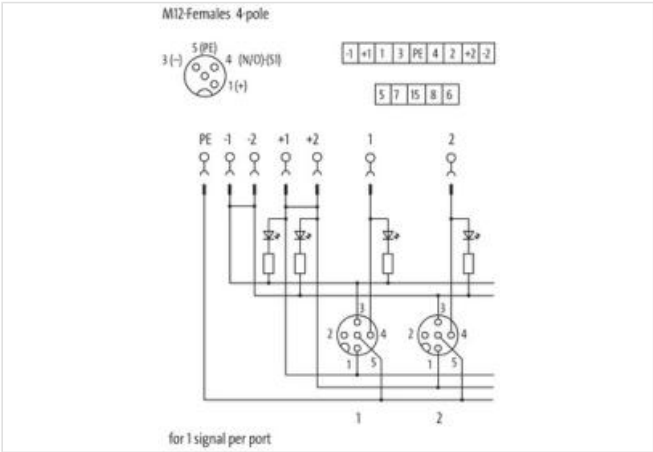

제품자료	
ECLASS-6.0	27143423
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440111
ECLASS-10.1	27440111

ECLASS-11.1	27440111
ECLASS-12.0	27440111
ETIM-5.0	EC002585
GTIN	4048879054164
세번부호	85369010
포장단위	1
Electrical data Supply	
Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current max.	8 A
Installation	
Connection cross section max.	1,5 mm²
AWG number max.	16
Installation Connection	
Connection	Screw plug-in terminals
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65, IP67
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C
Connection type 2	
Family construction form	Cap
No. of poles	14
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	4
PIN 1	+
PIN 2	n.c.
PIN 3	-
PIN 4	NO S 1
PIN 5	PE