



EXACT12, 8XM12, 5-POLE, CAP, PLUG. SPRING TERM.

Self wireable, PNP LED


- 8-way, 5-pole
- Form PNP
- Spring clamp plug-in terminals
- Plastic housings with good resistance against chemicals and oils.
- The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

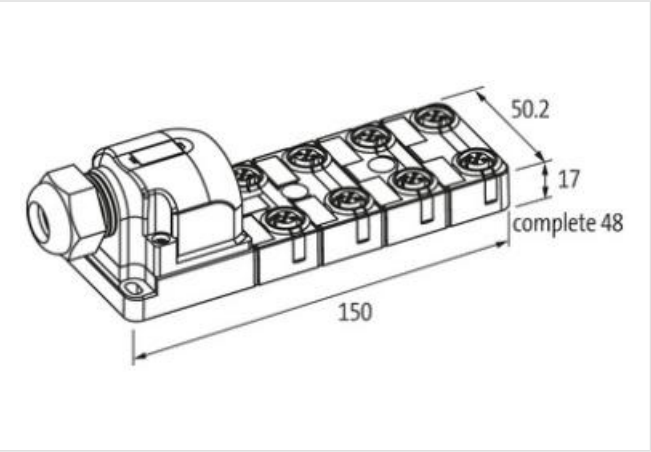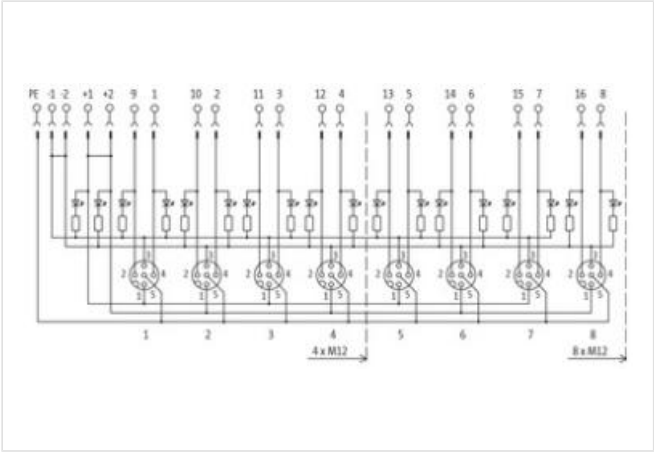

실제 제품은 이미지와 다를 수 있습니다.

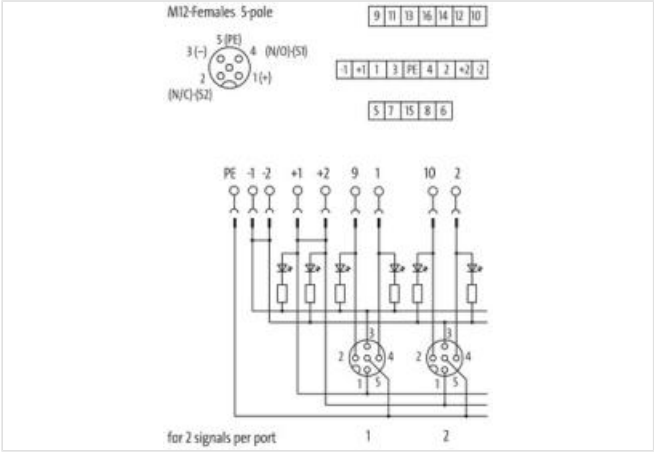

| 제품자료       |          |
|------------|----------|
| ECLASS-6.0 | 27143423 |
| ECLASS-6.1 | 27279219 |
| ECLASS-7.0 | 27279219 |
| ECLASS-8.0 | 27279219 |

|             |               |
|-------------|---------------|
| ECLASS-9.0  | 27440111      |
| ECLASS-10.1 | 27440111      |
| ECLASS-11.1 | 27440111      |
| ECLASS-12.0 | 27440111      |
| ETIM-5.0    | EC002585      |
| GTIN        | 4048879053853 |
| 세번부호        | 85369010      |
| 포장단위        | 1             |

Electrical data | Supply

|                                    |      |
|------------------------------------|------|
| Operating voltage DC               | 24 V |
| Current operating per contact max. | 4 A  |
| Total current max.                 | 8 A  |

Installation

|                               |                     |
|-------------------------------|---------------------|
| Connection cross section max. | 1,5 mm <sup>2</sup> |
| AWG number max.               | 16                  |

Installation | Connection

|            |                           |
|------------|---------------------------|
| Connection | Spring clamp terminals FK |
|------------|---------------------------|

Device protection | Electrical

|                                     |            |
|-------------------------------------|------------|
| Degree of protection (EN IEC 60529) | IP65, IP67 |
|-------------------------------------|------------|

Device protection | Media

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

Mechanical data | Material data

|                  |         |
|------------------|---------|
| Material housing | Plastic |
|------------------|---------|

Environmental characteristics | Climatic

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C  |

Connection type 2

|                          |        |
|--------------------------|--------|
| Family construction form | Cap    |
| No. of poles             | 21     |
| Family construction form | M12    |
| Gender                   | female |
| Color contact carrier    | black  |
| Coding                   | A      |
| No. of poles             | 5      |
| PIN 1                    | +      |
| PIN 2                    | NC S 2 |
| PIN 3                    | -      |
| PIN 4                    | NO S 1 |
| PIN 5                    | PE     |