



CAP BIG WITH PLUG. SCREW TERM. 21-POLE

For use with 4-,6-,8-way d-box M12 5-pole

Cap for 4-, 6-, and 8-way distribution box, 5-pole  
Screw plug-in terminals  
Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

제품 링크

일러스트

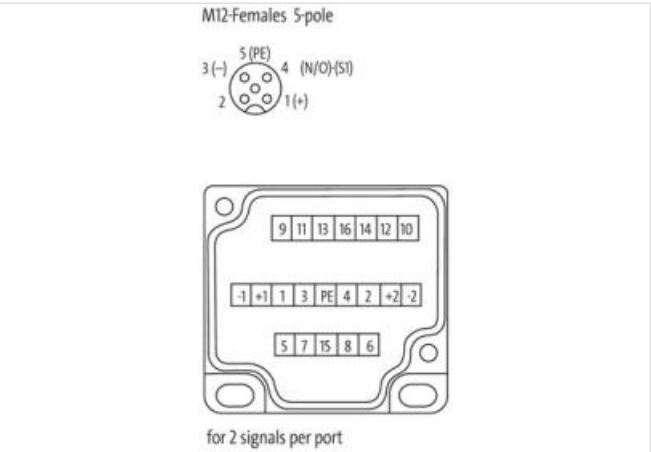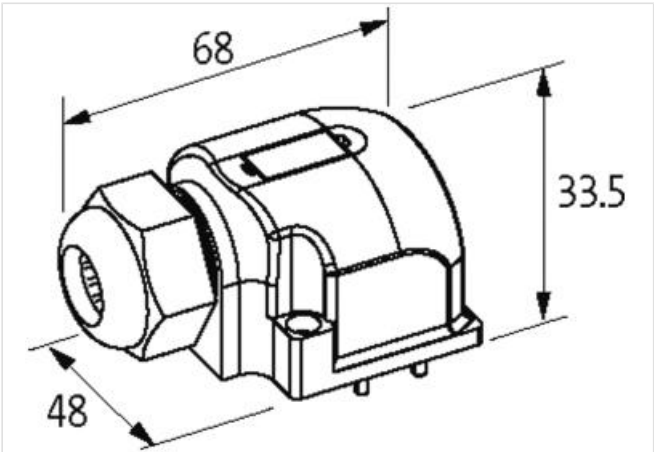

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |          |
|-------------|----------|
| ECLASS-6.0  | 27143423 |
| ECLASS-6.1  | 27279219 |
| ECLASS-7.0  | 27279219 |
| ECLASS-8.0  | 27279219 |
| ECLASS-9.0  | 27440108 |
| ECLASS-10.1 | 27440111 |

|                                          |                         |
|------------------------------------------|-------------------------|
| ECLASS-11.1                              | 27440111                |
| ECLASS-12.0                              | 27440111                |
| ETIM-5.0                                 | EC002585                |
| GTIN                                     | 4048879300056           |
| 세번부호                                     | 85369010                |
| 포장단위                                     | 1                       |
| Electrical data   Supply                 |                         |
| Total current max.                       | 8 A                     |
| Installation                             |                         |
| Connection cross section max.            | 1,5 mm²                 |
| AWG number max.                          | 16                      |
| Installation   Connection                |                         |
| Connection                               | Screw plug-in terminals |
| Device protection   Media                |                         |
| Flame resistance                         | flame retardant         |
| Mechanical data   Material data          |                         |
| Material housing                         | Plastic                 |
| Environmental characteristics   Climatic |                         |
| Operating temperature min.               | -20 °C                  |
| Operating temperature max.               | 80 °C                   |
| Connection type 1                        |                         |
| Family construction form                 | Cap                     |
| No. of poles                             | 21                      |