


Mico Pro Potential distributor 2 x 2 x 06

Multiplying two channels 5-times , max 20 A each channel

Mico Pro® PD 2× 2× 06
2 channels per (×5)
Build your own Mico Pro® online:
[START](#)

제품 링크

일러스트

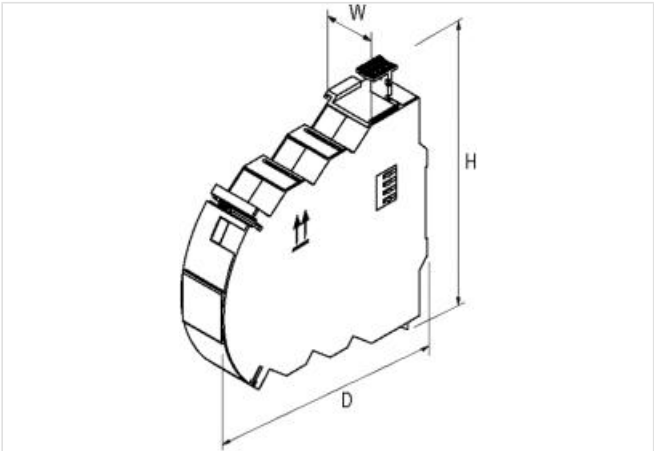

실제 제품은 이미지와 다를 수 있습니다.



제품자료

ECLASS-6.0	27141106
ECLASS-6.1	27371890
ECLASS-7.0	27371890
ECLASS-8.0	27371890
ECLASS-9.0	27371890
ECLASS-10.1	27371892
ECLASS-11.1	27371892
ECLASS-12.0	27371892
ETIM-5.0	EC000489
GTIN	4048879749237
세번부호	85363030
포장단위	1

Electrical data | Supply

Total current max.	20 A
--------------------	------

Electrical data | Input

Input voltage 1 DC	12 V
Input voltage 2 DC	24 V
Input voltage DC min.	9 V
Input voltage DC max.	30 V

Total current bridge set max.	40 A
Installation	
Connection cross-section static min.	0,2 mm²
Connection cross section static max.	2,5 mm²
Connection cross-section dynamic min.	0,2 mm²
Connection cross section dynamic max.	2,5 mm²
AWG number static min.	14
AWG number static max.	24
AWG number dynamic min.	14
AWG number dynamic max.	24
Installation Connection	
Connection	Bridge system
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	130 mm
Width	24 mm
Depth	114 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	55 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Connection type 9	
Family construction form	Bridging Contact
Gender	female
Color contact carrier	black
No. of poles	1
PIN 1	0 V
Family construction form	Bridging Contact
Gender	female
Color contact carrier	black
No. of poles	4
PIN 1	On
PIN 2	Ctrl
PIN 3	Alarm
PIN 4	0.9
Family construction form	Bridging Contact
Gender	male
Color contact carrier	black
No. of poles	4
PIN 1	On
PIN 2	Ctrl
PIN 3	Alarm
PIN 4	0.9
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4

PIN 1	6 U 1
PIN 2	6 0 V
PIN 3	12 U 2
PIN 4	12 0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	5 U 1
PIN 2	5 0 V
PIN 3	11 U2
PIN 4	11 0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	4 U 1
PIN 2	4 0 V
PIN 3	10 U 2
PIN 4	10 0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	3 U 1
PIN 2	3 0 V
PIN 3	9 U 2
PIN 4	9 0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	2 U 1
PIN 2	2 0 V
PIN 3	8 U 2
PIN 4	8 0 V
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	1 U 1
PIN 2	1 0 V
PIN 3	7 U 2
PIN 4	7 0 V