



MICO FUSE 250 FUSE HOLDER 5X20MM 8 CHANNELS

IN: 250V AC/DC OUT: 250V AC/DC / 6A AC/DC

MICO FUSE 250  
8 channels  
Total current: max. 40 A

제품 링크

일러스트

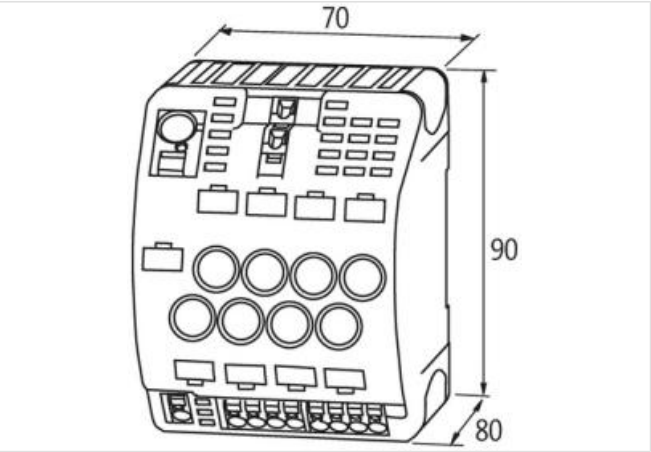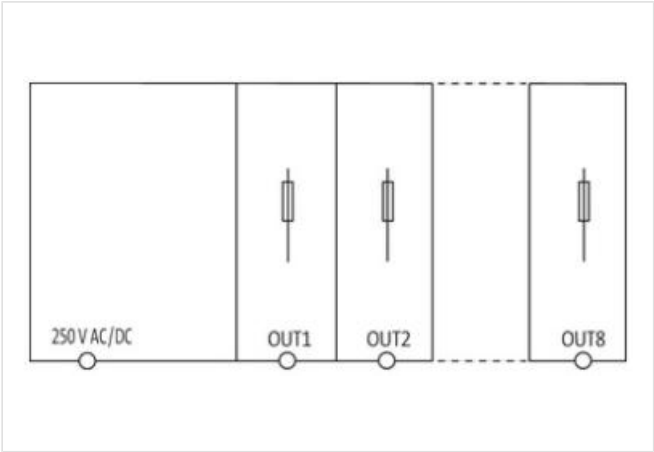

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |          |
|-------------|----------|
| ECLASS-6.0  | 27371802 |
| ECLASS-6.1  | 27142107 |
| ECLASS-7.0  | 27142121 |
| ECLASS-8.0  | 27142121 |
| ECLASS-9.0  | 27142121 |
| ECLASS-10.1 | 27142121 |

|                                          |                                |
|------------------------------------------|--------------------------------|
| ECLASS-11.1                              | 27142121                       |
| ECLASS-12.0                              | 27142121                       |
| ETIM-5.0                                 | EC001440                       |
| GTIN                                     | 4048879335270                  |
| 세번부호                                     | 85363030                       |
| 포장단위                                     | 1                              |
| Electrical data   Supply                 |                                |
| Operating voltage AC max.                | 250 V                          |
| Operating voltage DC max.                | 250 V                          |
| Operating current max.                   | 6 A                            |
| Total current max.                       | 40 A                           |
| Installation                             |                                |
| Connection cross-section inputs max.     | 16 mm²                         |
| Connection cross-section outputs min.    | 0,5 mm²                        |
| Connection cross-section outputs max.    | 4 mm²                          |
| Mechanical data   Mounting data          |                                |
| Mounting method                          | geschnappt                     |
| Suitable for mounting type               | Mounting rail TH35, (EN 60715) |
| Height                                   | 90 mm                          |
| Width                                    | 70 mm                          |
| Depth                                    | 80 mm                          |
| Environmental characteristics   Climatic |                                |
| Operating temperature min.               | -25 °C                         |
| Operating temperature max.               | 55 °C                          |
| Derating from                            | 40 °C                          |
| Connection type 3                        |                                |
| Connection                               | Spring clamp terminals FK      |
| Family construction form                 | terminal                       |
| Gender                                   | female                         |
| Color contact carrier                    | green                          |
| No. of poles                             | 1                              |
| PIN 1                                    | In                             |
| Connection                               | Spring clamp terminals FK      |
| Family construction form                 | terminal                       |
| Gender                                   | female                         |
| Color contact carrier                    | green                          |
| No. of poles                             | 4                              |
| PIN 1                                    | Out 1                          |
| PIN 2                                    | Out 2                          |
| PIN 3                                    | Out 3                          |
| PIN 4                                    | Out 4                          |
| Connection                               | Spring clamp terminals FK      |
| Family construction form                 | terminal                       |
| Gender                                   | female                         |
| Color contact carrier                    | green                          |
| No. of poles                             | 4                              |
| PIN 1                                    | Out 5                          |
| PIN 2                                    | Out 6                          |
| PIN 3                                    | Out 7                          |
| PIN 4                                    | Out 8                          |