

EMPARRO MEF 1/1 1-phase, 1-stage

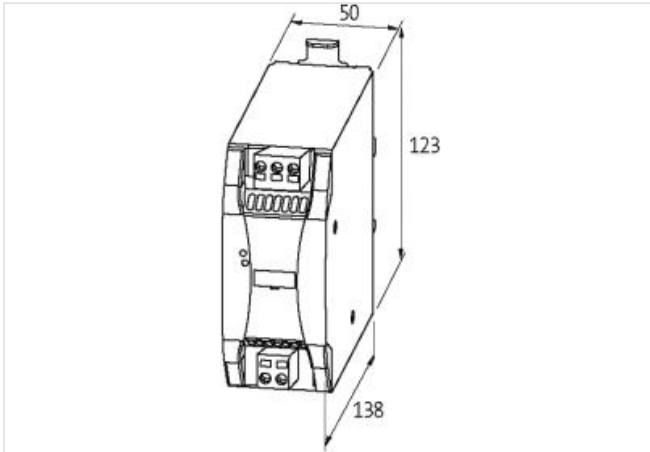
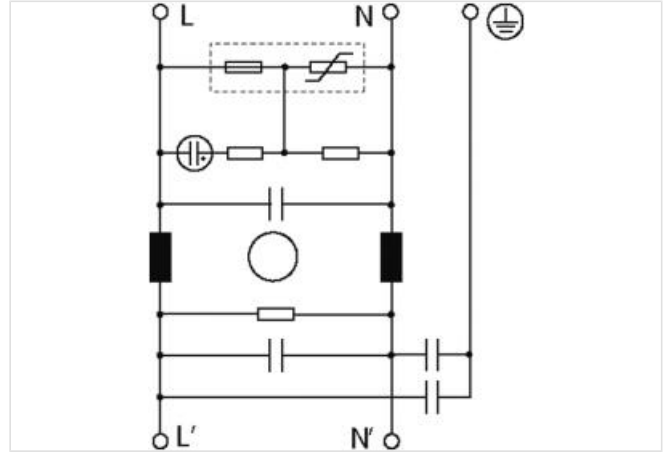
I:20A U:230 VAC, snap on, with surge protection

Over voltage protection

Current: 20 A

DIN-rail mountable

Attenuation curves on request.

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27130806
ECLASS-6.1	27420201
ECLASS-7.0	27420290
ECLASS-8.0	27420290
ECLASS-9.0	27420290
ECLASS-10.1	27420208

ECLASS-11.1	27420208
ECLASS-12.0	27420208
ETIM-5.0	EC002498
GTIN	4048879464468
Gümrük tarife no (gtip)	85363030
Paket miktarı	1

Electrical data

Leakage current max.	1 mA @ 250 V AC, 50 Hz
----------------------	------------------------

Electrical data | Supply

Power frequency	50 ... 60 Hz
Operating voltage AC min.	85 V
Operating voltage AC max.	265 V
Operating voltage DC min.	100 V
Operating voltage DC max.	230 V

Installation

Connection cross-section solid min.	1,5 mm ²
Connection cross-section solid max.	10 mm ²
Connection cross-section stranded/fine-stranded min.	1,5 mm ²
Connection cross-section stranded/fine-stranded max.	6 mm ²
AWG number solid min.	16
AWG number solid max.	8
AWG number stranded/fine stranded min.	16
AWG number stranded/fine stranded max.	10

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	123 mm
Width	50 mm
Depth	138 mm

Environmental characteristics | Climatic

Environmental class (IEC 60721)	3K3
---------------------------------	-----

Connection type 2

Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	L'
PIN 2	N'
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	3
PIN 1	L
PIN 2	N
PIN 3	PE