

**UNIVERSAL CONTACTOR SUPPRESSOR**

RC, 230VAC/DC/25VA/W



230 V AC/DC

RC

For other configurations and voltages, please inquire.

**Ürün Linki**

örnekleme

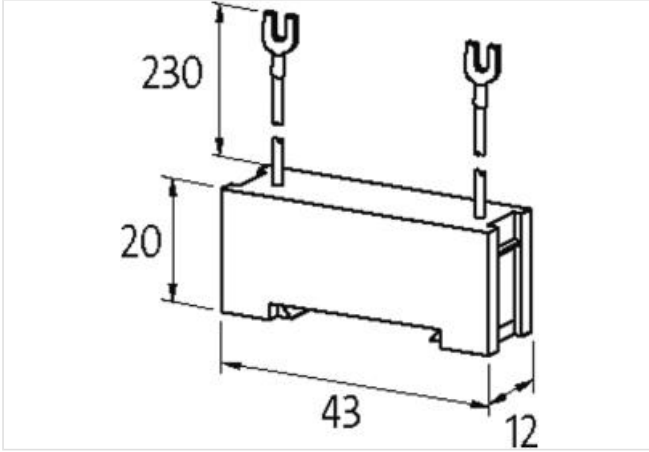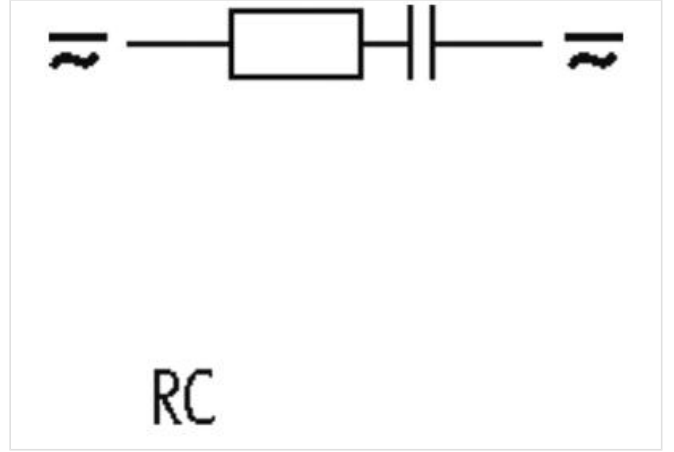

Ürün Image farklı olabilir

**Ticari bilgiler**

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27371013 |
| ECLASS-6.1  | 27371013 |
| ECLASS-7.0  | 27371013 |
| ECLASS-8.0  | 27371013 |
| ECLASS-9.0  | 27371013 |
| ECLASS-10.1 | 27371013 |

|                                                 |               |
|-------------------------------------------------|---------------|
| ECLASS-11.1                                     | 27371013      |
| ECLASS-12.0                                     | 27371013      |
| ETIM-5.0                                        | EC002498      |
| GTIN                                            | 4048879020602 |
| Gümrük tarife no (gtip)                         | 85363010      |
| Paket miktarı                                   | 1             |
| <b>Compatibility   Compatible with</b>          |               |
| Appropriate contactors                          | universal     |
| <b>Electrical data</b>                          |               |
| Holding power max.                              | 25 W          |
| <b>Electrical data   Input</b>                  |               |
| Input voltage AC min.                           | 110 V         |
| Input voltage AC max.                           | 250 V         |
| Input voltage DC min.                           | 110 V         |
| Input voltage DC max.                           | 250 V         |
| <b>Mechanical data   Mounting data</b>          |               |
| Height                                          | 20 mm         |
| Width                                           | 43 mm         |
| Depth                                           | 12 mm         |
| <b>Environmental characteristics   Climatic</b> |               |
| Operating temperature min.                      | -20 °C        |
| Operating temperature max.                      | 70 °C         |