

ALLEN-BRADLEY CONTACTOR SUPPRESSOR

RC, 240VAC/DC



230 V AC/DC

RC

For other configurations and voltages, please inquire.

Ürün Linki

örnekleme

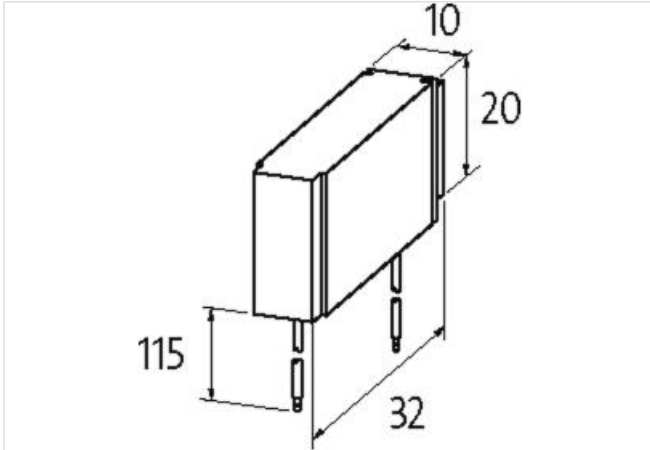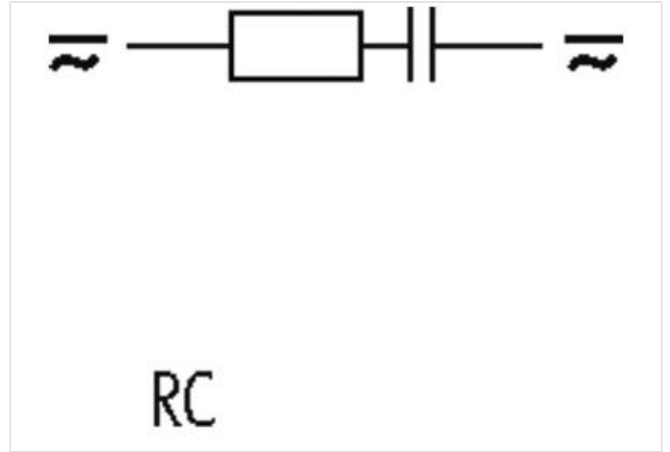

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
GTIN	4048879020060
Gümrük tarife no (gtip)	85363010
Paket miktarı	1

Compatibility | Compatible with

Appropriate contactors	100-M
------------------------	-------

Electrical data

Bu veri sayfasındaki bilgiler en büyük özenle hazırlandı.
Bilgilerin doğruluğu bütünlüğü ve güncelliği konusunda yükümlülük ihmalı sınırlıdır. Sürüm: 2024-04-25

Damping factor	1.5× UN
----------------	---------

Electrical data | Input

Input voltage AC min.	110 V
-----------------------	-------

Input voltage AC max.	250 V
-----------------------	-------

Input voltage DC min.	110 V
-----------------------	-------

Input voltage DC max.	250 V
-----------------------	-------

Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
-------------------------------------	-----

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Height	20 mm
--------	-------

Width	10 mm
-------	-------

Depth	32 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	70 °C
----------------------------	-------