

**SIEMENS CONTACTOR SUPPRESSOR**

RC, 110VAC/DC

48 V AC/DC



110 V AC/DC

RC

For other configurations and voltages, please inquire.

**Ürün Linki**

örnekleme

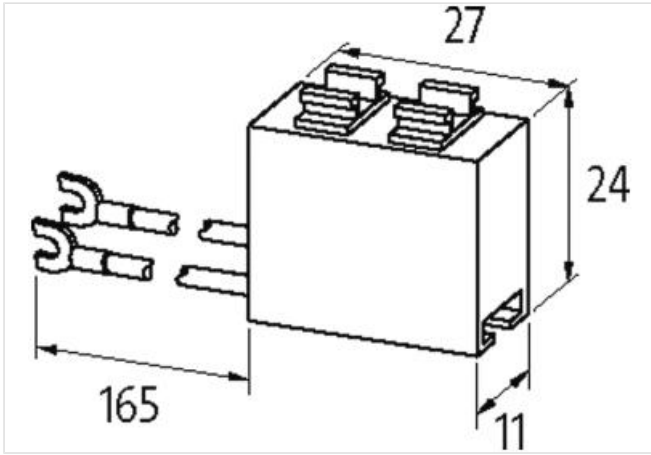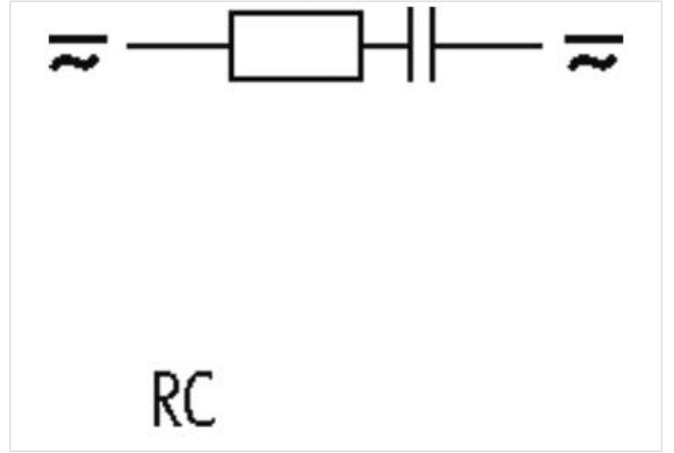

Ürün Image farklı olabilir

**Ticari bilgiler**

|             |          |
|-------------|----------|
| ECLASS-6.0  | 27371013 |
| ECLASS-6.1  | 27371013 |
| ECLASS-7.0  | 27371013 |
| ECLASS-8.0  | 27371013 |
| ECLASS-9.0  | 27371013 |
| ECLASS-10.1 | 27371013 |

|                                                 |                                             |
|-------------------------------------------------|---------------------------------------------|
| ECLASS-11.1                                     | 27371013                                    |
| ECLASS-12.0                                     | 27371013                                    |
| ETIM-5.0                                        | EC002498                                    |
| GTIN                                            | 4048879019798                               |
| Gümrük tarife no (gtip)                         | 85363010                                    |
| Paket miktarı                                   | 1                                           |
| <b>Compatibility   Compatible with</b>          |                                             |
| Appropriate contactors                          | 3 TH 3/4/8; 3 TF 30...45; 3 TB 40...3 TB 44 |
| <b>Electrical data</b>                          |                                             |
| Damping factor                                  | 1.5× UN                                     |
| <b>Electrical data   Input</b>                  |                                             |
| Input voltage AC min.                           | 48 V                                        |
| Input voltage AC max.                           | 127 V                                       |
| Input voltage DC min.                           | 48 V                                        |
| Input voltage DC max.                           | 127 V                                       |
| <b>Installation   Connection</b>                |                                             |
| Connection information                          | self-securing cable forks                   |
| <b>Device protection   Media</b>                |                                             |
| Flame resistance                                | flame retardant                             |
| <b>Mechanical data   Material data</b>          |                                             |
| Combustibility class housing (UL94)             | V-0                                         |
| Material housing                                | Plastic                                     |
| <b>Mechanical data   Mounting data</b>          |                                             |
| Height                                          | 11 mm                                       |
| Width                                           | 27 mm                                       |
| Depth                                           | 24 mm                                       |
| <b>Environmental characteristics   Climatic</b> |                                             |
| Operating temperature min.                      | -20 °C                                      |
| Operating temperature max.                      | 70 °C                                       |