

MOTOR SUPPRESSOR

RC, 3x400VAC/20kW


3x 400 V AC

RC single


Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Ürün Linki

örnekleme

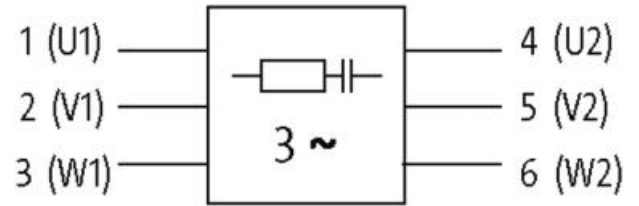

RC-(1) per phase

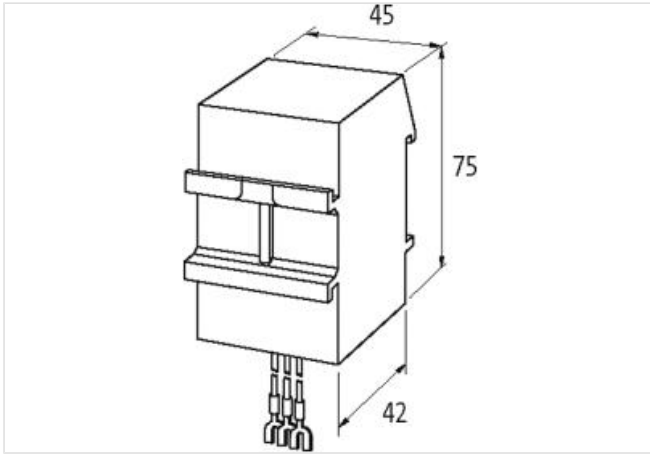

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013

ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879019583
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	400 V
Installation	
Connection cross-section stranded/fine-stranded min.	0,5 mm²
Installation Connection	
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4
Length single strands	250 mm
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Height	75 mm
Width	45 mm
Depth	42 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C