

MOTOR SUPPRESSOR

Varistor, 3x400VAC/7,5kW

3x 400 V AC

VDR



isolated M6

PG9

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Ürün Linki

örnekleme

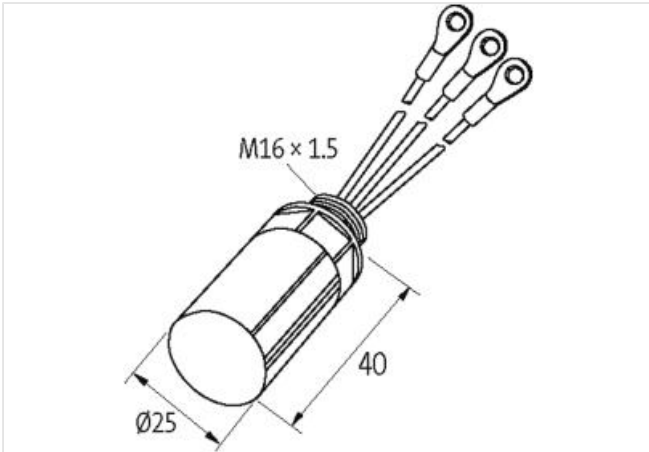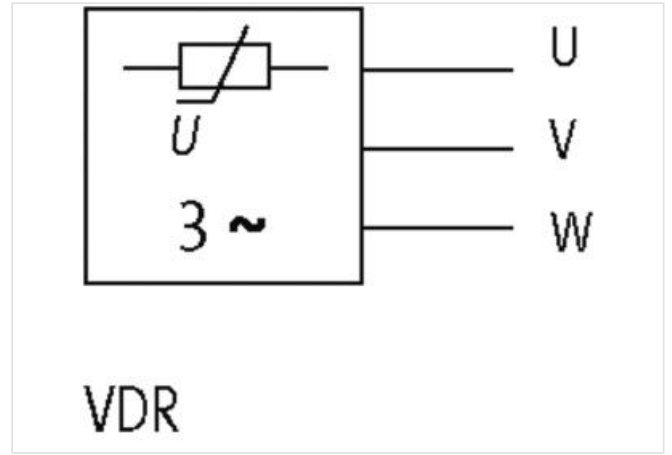

Ürün Image farklı olabilir

**Ticari bilgiler**

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013

ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879019309
Gümrük tarife no (gtip)	85363010
Paket miktarı	1

Electrical data | Supply

Power frequency	10 ... 400 Hz
-----------------	---------------

Electrical data | Input

Input voltage AC	400 V
------------------	-------

Installation

Connection cross section max.	0,5 mm ²
-------------------------------	---------------------

Installation | Connection

Connection information	Single strands
Length single strands	100 mm
Ring terminals	M6isolated

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	25 mm
Width	25 mm
Depth	40 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C