

MOTOR SUPPRESSOR

Varistor, 3x400VAC/4kW

3x 400 V AC



VDR

isolated M4

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Ürün Linki

örnekleme

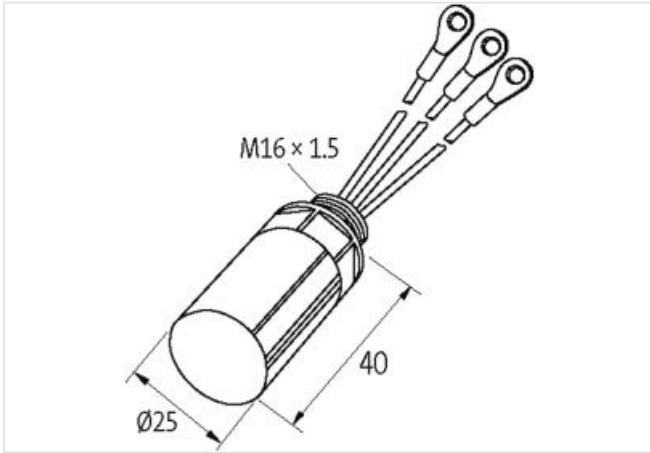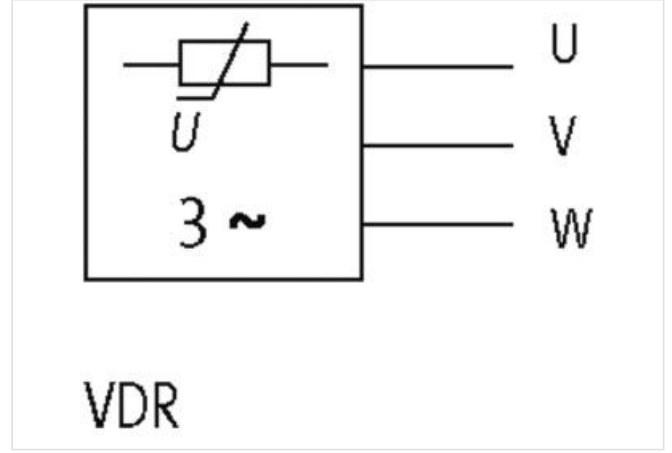

Ürün Image farklı olabilir



Ticari bilgiler

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013

ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000197
GTIN	4048879019248
Gümrük tarife no (gtip)	85363010
Paket miktarı	1
Electrical data Supply	
Power frequency	10 ... 400 Hz
Electrical data Input	
Input voltage AC	400 V
Installation	
Connection cross section max.	0,5 mm ²
Installation Connection	
Connection information	Single strands
Length single strands	100 mm
Ring terminals	M4isolated
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Combustibility class housing (UL94)	V-0
Material housing	Plastic
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Height	25 mm
Width	25 mm
Depth	40 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C